

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1202480014](#)
Status: **Active**
Overview: Brad Passive-Signal and Safety MPIS Boxes
Description: MPIS Micro-Change (M12) Passive Junction Box, Top-Mount, 6 Ports, LED for PNP Sensor, WSOR Cable, 10.0m Length

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

UL E152210

General

Product Family Passive Distribution Boxes
 Series [120248](#)
 IP Rating IP67
 Overview [Brad Passive-Signal and Safety MPIS Boxes](#)
 Product Name MPIS
 UPC 889056329668

Physical

Bus I/O N/A
 Cable Connector Orientation Straight
 Cable Length 10.0m
 Home Run Cable Length 10.0m
 Home Run Connector N/A
 Home Run Interface Pigtail
 Keyway A-coded
 LED Indicator PNP Sensors
 Material - Cable Jacket TPU
 Material - Housing PBT
 Material - Metal Copper Alloy
 Material - Plating Mating Gold
 Net Weight 1237.510/g
 Orientation Top-Mount
 Poles 4
 Poles (wired) 4
 Ports 6
 Temperature Range - Operating -25°C to +85°C
 Wire/Cable Type WSOR
 Wiring Configuration Single I/O per Port

Electrical


Current - Maximum per Contact 12.0A per module, 4.0A per port
 Functional Wiring PNP
 Voltage - Maximum 10-30V DC

Material Info

Engineering Number BTB600P-FBW-10

Reference - Drawing Numbers

Sales Drawing 1202480010-000

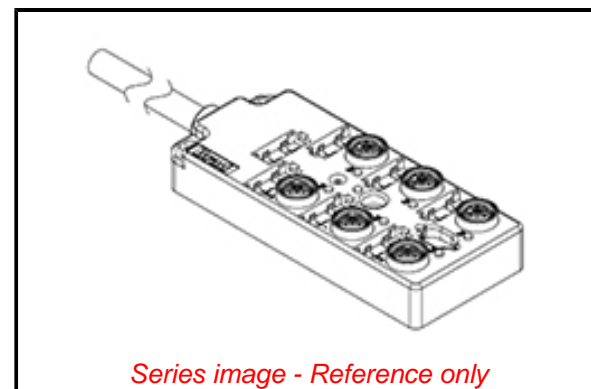

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant with Exemption 6(c)

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

50 Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

[120248 Series](#)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[1202480014](#)