

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1203410600](#)
Status: **Active**
Overview: [Brad Industrial Ethernet Solutions](#)
Description: Standard RJ-45 CAT6A Double-Ended Cordset, 8 Poles, Male (Straight) to Male (Straight), 26 AWG, Shielded PUR Cable, 0.50m (1.64') Length

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Packaging Specification PK-120341-600-001 \(PDF\)](#)

General

Product Family	Industrial Cordsets
Series	120341
Connector End A	RJ-45 (standard)
Connector End B	RJ-45 (standard)
IP Rating	IP20
Material - Contact	Brass
Overview	Brad Industrial Ethernet Solutions
Performance Category	6A
Product Name	RJ45
Protocol	N/A
Region	America, Asia, Europe
Type	Double Ended
UPC	887191678290

Physical

Cable Diameter	6.40mm (.252")
Cable Length	0.50m (1.64')
Color - Cable Jacket	Blue
Coupling Style	Threaded
Gender	Male-Male
Keyway	N/A
LED Indicator	No
Material - Cable Jacket	PUR
Material - Connector Body	PUR
Material - Coupling Nut	N/A
Material - Plating Mating	Gold
Net Weight	40.700/g
Orientation	Straight to Straight
Poles	8
Temperature Range - Operating	-40°C to +70°C
Wire Size AWG	26
Wire/Cable Type	Shielded PUR

Electrical


Current - Maximum per Contact	0.5A
Voltage - Maximum	48V

Material Info

Engineering Number	E66E06020M005
--------------------	---------------

Reference - Drawing Numbers

Packaging Specification	PK-120341-600-001
-------------------------	-------------------

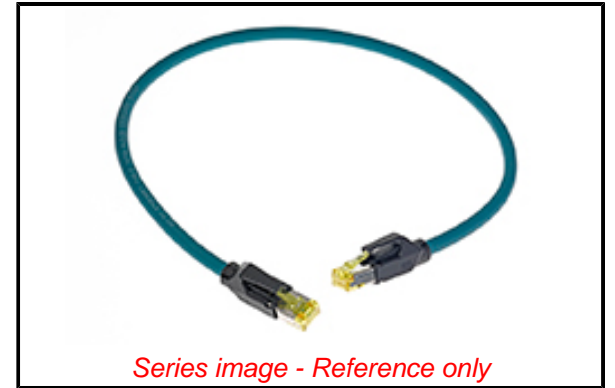

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

Search Parts in this Series

[120341](#) Series

Mates With

[120341](#) Micro-Change CAT6A Receptacles

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[1203410600](#)