

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1210641756](#)
Status: **Active**
Overview: mPm DIN Valve Connectors
Description: mPm DIN Valve Connector, Form A-18mm, PG7 Internal Threads, 2 Pole Plus Ground Terminal, 250V AC/300V DC, Red LED, Transparent, Nitrile Gasket

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Packaging Specification PK-121064-S18-001 \(PDF\)](#)

Agency Certification

UL E218123

General

Product Family Field Attachable / Accessories
 Series [121064](#)
 Form A - 18mm
 IP Rating IP65, IP67
 Material - Contact Brass
 Overview [mPm DIN Valve Connectors](#)
 Product Name mPm
 Type Field Attachable Connector
 UPC 884982302198

Physical

Cable Diameter N/A
 Coupling Type Internal Thread
 Diagnostics / LEDs Yes
 Diagnostics Port No
 Gender N/A
 Keyway None
 Material - Connector Body Polypropylene
 Material - Coupling Nut N/A
 Material - Plating Mating Silver
 Net Weight 21.762/g
 Orientation 90° Angle
 Pitch - Mating Interface 18.00mm
 Poles 2
 Temperature Range - Operating -40°C to +90°C
 Wire Size AWG N/A

Electrical


Current - Maximum per Contact 16.0A
 Voltage - Maximum 250V AC / 300V DC

Material Info

Engineering Number S182M6TC321

Reference - Drawing Numbers

Packaging Specification PK-121064-S18-001
 Sales Drawing SD-121064-002-000

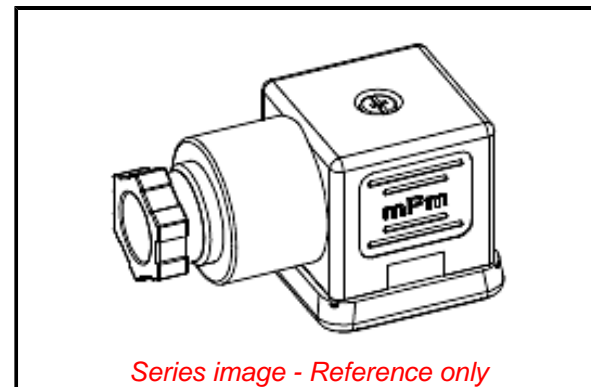

Series image - Reference only

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

Search Parts in this Series

[121064 Series](#)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[1210641756](#)