

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1300061435](#)
Status: **Active**
Overview: Brad Mini-Change Connectors
Description: Mini-Change A-Size Single-Ended Cordset, 5 Poles, Male (Straight) to Pigtail, 16 AWG, PVC Cable, 0.91m (3.0') Length

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA LR6837
 UL E152210

General

Product Family Industrial Cordsets
 Series [130006](#)
 Connector End A Mini-Change
 Connector End B Pigtail
 IP Rating IP67
 Material - Contact Brass
 Overview [Brad Mini-Change Connectors](#)
 Product Name Mini-Change
 Protocol DeviceNet
 Region America
 Type Single Ended
 UPC 78678843404

Physical

Cable Diameter 12.70mm (.500")
 Cable Length 0.91m (3.0')
 Color - Cable Jacket Yellow
 Coupling Style Threaded
 Gender Male-Pigtail
 Keyway Single
 LED Indicator No
 Material - Cable Jacket PVC
 Material - Connector Body TPE
 Material - Coupling Nut Black Epoxy Coated Zinc
 Material - Plating Mating Gold
 Orientation Straight to Pigtail
 Poles 5
 Temperature Range - Operating -20°C to +105°C
 Wire Size AWG 16
 Wire/Cable Type ST00W

Electrical


Current - Maximum per Contact 8.0A
 Voltage - Maximum 600V

Material Info

Engineering Number 105002A01F030

Reference - Drawing Numbers

Sales Drawing SD-130006-005-001

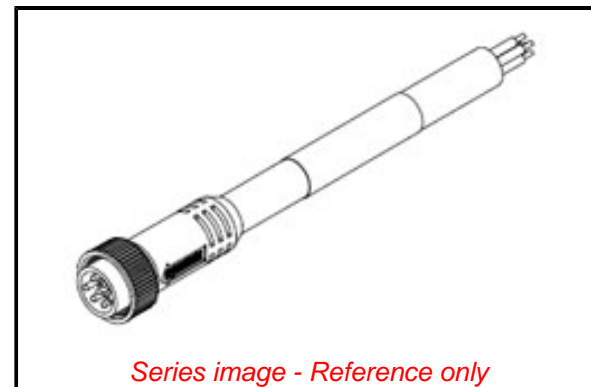

Series image - Reference only

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

Search Parts in this Series

[130006 Series](#)

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[130006-1435](#)