

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: **1300108036**
Status: **Active**
Overview: Brad Mini-Change Connectors
Description: Mini-Change Double-Ended Cordset, 5 Poles, Male (90°) to Female (90°), 16 AWG, PUR Cable, 1.0m (3.28') Length

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family	Industrial Cordsets
Series	<u>130010</u>
Connector End A	Mini-Change
Connector End B	Mini-Change
IP Rating	IP67
Material - Contact	Copper Alloy
Overview	<u>Brad Mini-Change Connectors</u>
Product Name	Mini-Change
Protocol	FF
Region	Europe
Type	Double Ended
UPC	887191260808

Physical

Cable Diameter	12.70mm (.500")
Cable Length	1.0m (3.28')
Color - Cable Jacket	Gray
Coupling Style	Threaded
Gender	Female-Male
Keyway	Single
LED Indicator	No
Material - Cable Jacket	PUR
Material - Connector Body	PUR
Material - Coupling Nut	Black Epoxy Coated Zinc
Material - Plating Mating	Gold
Orientation	90° to 90°
Poles	5
Temperature Range - Operating	-20°C to +80°C
Wire Size AWG	16
Wire/Cable Type	UL 20233

Electrical


Current - Maximum per Contact	8.0A
Voltage - Maximum	300V AC/DC

Material Info

Engineering Number	115033B21M010
--------------------	---------------

Reference - Drawing Numbers

Sales Drawing	SD-130010-025
---------------	---------------

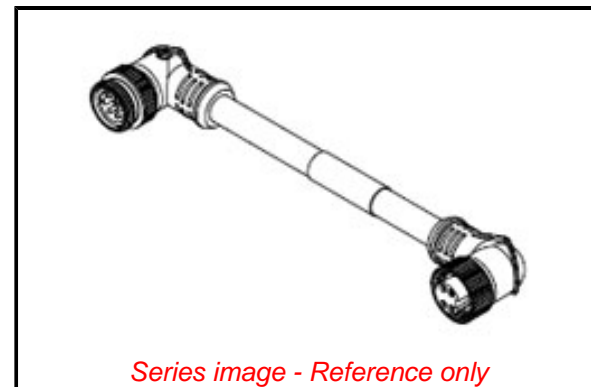

Series image - Reference only

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

Search Parts in this Series

130010 Series

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[1300108036](#)