

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [1300130388](#)  
**Status:** **Active**  
**Overview:** [Brad Mini-Change Connectors](#)  
**Description:** Mini-Change A-Size Bulkhead Feed-Through, 4 Poles, 7/8-16UN, Nickel Plated Brass, 0.049m (1.94") Length, 300V

**Documents:**

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

**Agency Certification**

CSA LR6837

**General**

Product Family Industrial Receptacles  
 Series [130013](#)  
 IP Rating IP67  
 NEMA Rating NEMA 6  
 Overview [Brad Mini-Change Connectors](#)  
 Product Name Mini-Change  
 Type Bulkhead Feed-Through  
 UPC 78172553866

**Physical**

Coupling Type Internal Thread  
 Gender Female-Male  
 Keyway Single  
 Length 0.049m  
 Material - Component Nickel-plated Brass  
 Mounting Thread Size 7/8" - 16 UN-2A  
 Net Weight 91.172/g  
 Orientation Straight  
 Panel Mount Front  
 Poles 4  
 Temperature Range - Operating -20° to +80°C  
 Wire Size AWG N/A  
 Wire/Cable Type N/A

**Electrical**


Current - Maximum per Contact 8.0A  
 Voltage - Maximum 300V AC/DC

**Material Info**

Engineering Number 1R4030

**Reference - Drawing Numbers**

Sales Drawing SD-130013-001-001

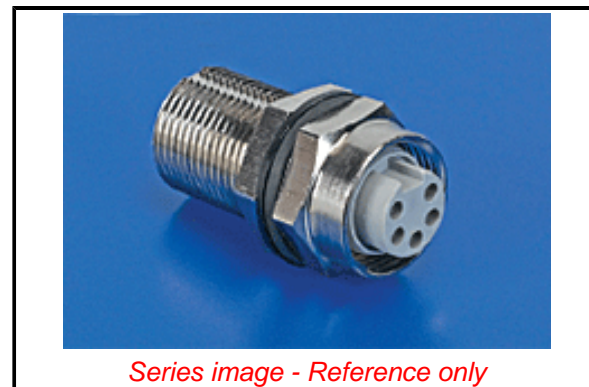

*Series image - Reference only*

**EU ELV**

**Not Relevant**

**EU RoHS**

**Compliant with Exemption 6(c)**

**REACH SVHC**

Contained Per - D(2020)9139-DC (19 Jan 2021)

Lead

**Halogen-Free**

**Status**

**Not Reviewed**

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

**China RoHS**

50 Image

Not Relevant

Not Contained

**Search Parts in this Series**

[130013 Series](#)

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[130013-0388](#)