

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1300238023](#)
Status: **Active**
Description: Brad M16 Single-Ended Cordset, 14 Poles, 8 Ports, Female (90°) to Pigtail, 0.75mm²/0.34mm² (19/22 AWG), WSOR Cable, 10.0m (32.81') Length

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family	Industrial Cordsets
Series	130023
Connector End A	M16
Connector End B	Pigtail
IP Rating	IP67
Material - Contact	Copper Alloy
Product Name	Brad M16
Type	Single Ended
UPC	889056141499

Physical

Cable Diameter	9.20mm (.362")
Cable Length	10.0m (32.81')
Color - Cable Jacket	Black
Coupling Style	Threaded
Gender	Female-Pigtail
Keyway	Single
LED Indicator	No
Material - Cable Jacket	TPU
Material - Connector Body	PUR
Material - Coupling Nut	Brass
Material - Plating Mating	Gold
Net Weight	1200.000/g
Orientation	90° to Pigtail
Poles	14
Temperature Range - Operating	-25°C to +80°C
Wire Size AWG	19, 22
Wire/Cable Type	WSOR

Electrical


Current - Maximum per Contact	3.0A
Voltage - Maximum	60V AC

Material Info

Engineering Number	L04101B78M100
--------------------	---------------

Reference - Drawing Numbers

Sales Drawing	1300238023-000
---------------	----------------

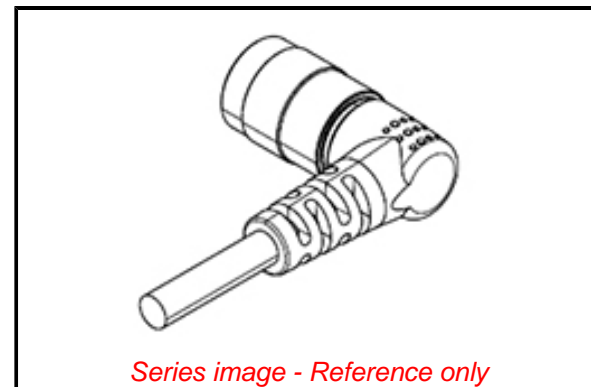

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
ED/30/2017 (7 July
2017)

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Not Relevant

Not Contained

Search Parts in this Series

[130023 Series](#)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[130023-8023](#)