

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [1300238030](#)  
**Status:** **Active**  
**Description:** Brad M16 Single-Ended Cordset, 14 Poles, 10 Ports, Female (90°) to Pigtail, 0.75mm<sup>2</sup>/0.34mm<sup>2</sup> (19/22 AWG), WSOR Cable, 15.0m (49.21')

**Documents:**

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

**General**

Product Family	Industrial Cordsets
Series	<a href="#">130023</a>
Connector End A	M16
Connector End B	Pigtail
IP Rating	IP67
Material - Contact	Copper Alloy
Product Name	Brad M16
Protocol	N/A
Type	Single Ended
UPC	889056141567

**Physical**

Cable Diameter	8.80mm (.346")
Cable Length	15.0m (49.21')
Color - Cable Jacket	Black
Coupling Style	Threaded
Gender	Female-Pigtail
Keyway	Single
LED Indicator	No
Material - Cable Jacket	TPU
Material - Connector Body	PUR
Material - Coupling Nut	Brass
Material - Plating Mating	Gold
Orientation	90° to Pigtail
Poles	14
Temperature Range - Operating	-25°C to +80°C
Wire Size AWG	19, 22
Wire/Cable Type	WSOR

**Electrical**


Current - Maximum per Contact	3.0A
Voltage - Maximum	60V AC

**Material Info**

Engineering Number	L04A01B78M150
--------------------	---------------

**Reference - Drawing Numbers**

Sales Drawing	1300238025-000
---------------	----------------

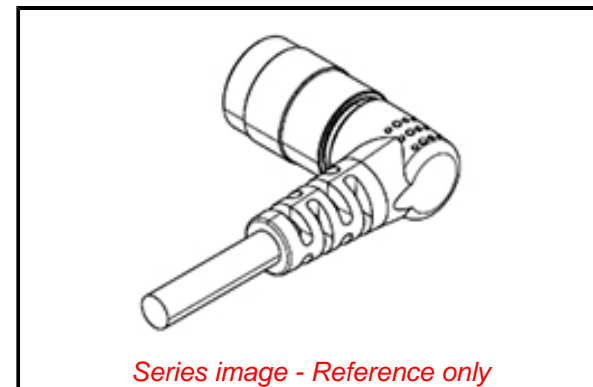

*Series image - Reference only*

**EU ELV**

**Not Reviewed**

**EU RoHS**

**Not Reviewed**

**REACH SVHC**

Not Reviewed

**Halogen-Free**

**Status**

**Not Reviewed**

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

**Search Parts in this Series**

[130023 Series](#)

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[1300238030](#)