

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1300250259](#)
Status: **Active**
Overview: [Brad Mini-Change Connectors](#)
Description: Mini-Change Single-Ended Cordset, 5 Poles, Male (Straight) to Female (90°) 16 and 20 AWG, DeviceNet Mid Cable, 1.0m (3.28') Length

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA LR6837

General

Product Family Industrial Cordsets
 Series [130025](#)
 Connector End A Mini-Change
 Connector End B Mini-Change
 IP Rating IP67
 Material - Contact Brass
 Overview [Brad Mini-Change Connectors](#)
 Product Name DeviceNet Trunk, Mini-Change
 Region Europe
 Type Double Ended
 UPC 78678898103

Physical

Cable Diameter 8.38mm (.330")
 Cable Length 1.0m (3.28')
 Color - Cable Jacket Gray
 Coupling Style Threaded
 Gender Female-Male
 Keyway Single
 LED Indicator No
 Material - Cable Jacket PVC
 Material - Connector Body PVC
 Material - Coupling Nut Die-Cast Zinc
 Material - Plating Mating Gold
 Orientation 90° to Straight
 Poles 5
 Temperature Range - Operating -20° to +80°C
 Wire Size AWG 16, 20
 Wire/Cable Type Mid Cable

Electrical


Current - Maximum per Contact 4.0A
 Voltage - Maximum 300V AC/DC

Material Info

Engineering Number DNB91A-M010

Reference - Drawing Numbers

Sales Drawing SD-130025-010-001

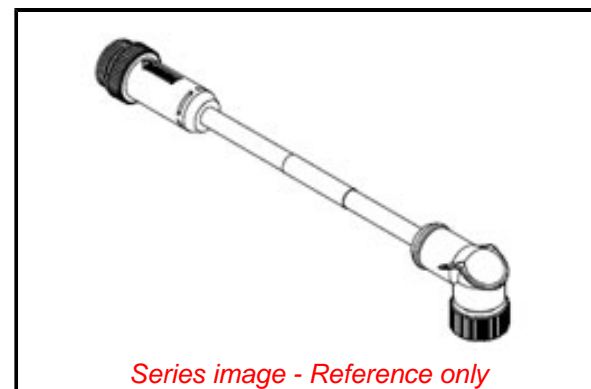

Series image - Reference only

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

Search Parts in this Series

[130025 Series](#)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[1300250259](#)