

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1300270052](#)
Status: **Active**
Overview: [DeviceNet Solutions](#)
Description: Micro-Change (M12) Single-Ended Cordset, 5 Poles, Female (Straight) to Pigtail, 22 AWG, DeviceNet Cable Plus Drain, 5.0m (16.40') Length

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA LR6837
 UL E152210

General

Product Family Industrial Cordsets
 Series [130027](#)
 Connector End A Micro-Change (M12)
 Connector End B Pigtail
 IP Rating IP67
 Material - Contact Copper Alloy
 Overview [DeviceNet Solutions](#)
 Product Name DeviceNet, Micro-Change (M12)
 Protocol N/A
 Region Europe
 Type Single Ended
 UPC 78678830007

Physical

Cable Diameter 7.24mm (.285")
 Cable Length 5.0m (16.40')
 Color - Cable Jacket Gray
 Coupling Style Threaded
 Gender Female-Pigtail
 Keyway Single
 LED Indicator No
 Material - Cable Jacket PVC
 Material - Connector Body TPE
 Material - Coupling Nut Die-Cast Zinc
 Material - O-Ring Nitrile Rubber
 Material - Plating Mating Gold
 Net Weight 123.910/g
 Orientation Straight to Pigtail
 Poles 5
 Temperature Range - Operating -20°C to +80°C
 Wire Size AWG 22
 Wire/Cable Type Thin (Drop)

Electrical


Current - Maximum per Contact 4.0A
 Voltage - Maximum 250V AC/DC

Material Info

Engineering Number DND20A-M050

Reference - Drawing Numbers

Sales Drawing SD-130027-007-001

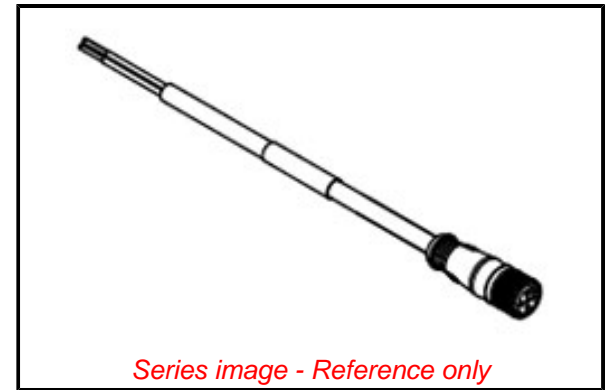

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
 D(2020)9139-DC (19
 Jan 2021)

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Not Relevant

Not Contained

Search Parts in this Series

[130027 Series](#)

This document was generated on 08/26/2021

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[1300270052](#)