

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: **1300290005**
Status: **Active**
Overview: Brad Nano-Change (M8) Products
Description: Nano-Change (M8) Single-Ended Cordset, 5 Poles, Male (90°) to Pigtail, 26 AWG, PVC Cable, 1.0m (3.28') Length

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family	Industrial Cordsets
Series	<u>130029</u>
Connector End A	Nano-Change (M8)
Connector End B	Pigtail
IP Rating	IP67
Material - Contact	Copper Alloy
Overview	<u>Brad Nano-Change (M8) Products</u>
Product Name	Nano-Change (M8)
Protocol	N/A
Region	Europe
Type	Single Ended
UPC	78678882267

Physical

Cable Diameter	N/A
Cable Length	1.0m (3.28')
Color - Cable Jacket	Gray
Coupling Style	Threaded
Gender	Male-Pigtail
Keyway	None
LED Indicator	No
Material - Cable Jacket	PVC
Material - Connector Body	TPE
Material - Coupling Nut	Nickel-plated Brass
Material - O-Ring	Fluoro-elastomer
Material - Plating Mating	Gold
Orientation	90° to Pigtail
Poles	5
Temperature Range - Operating	-20°C to +70°C
Wire Size AWG	26
Wire/Cable Type	Shielded-Twisted Pair

Electrical


Current - Maximum per Contact	1.68A
Voltage - Maximum	300V DC

Material Info

Engineering Number	405007D12M010
--------------------	---------------

Reference - Drawing Numbers

Sales Drawing	SD-130029-005
---------------	---------------

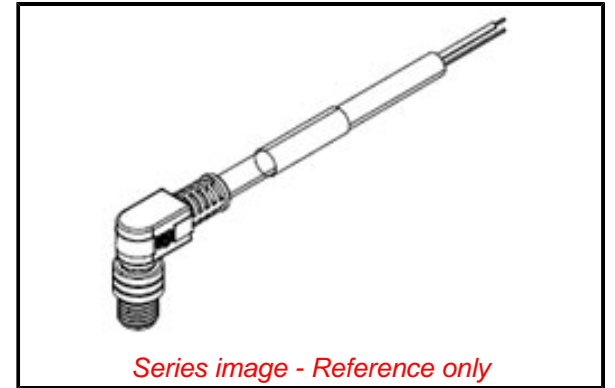

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

Search Parts in this Series

130029 Series

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[1300290005](#)