

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1300370005](#)
Status: **Active**
Overview: [DeviceNet Solutions](#)
Description: DeviceNet Micro-Change (M12), Top Mount, 4 Port, 5 Pole, with Mini-Change Connector on 2.0m Cable

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family	Passive Distribution Boxes
Series	130037
IP Rating	IP67
NEMA Rating	NEMA 6
Overview	DeviceNet Solutions
Product Name	DeviceNet, Micro-Change (M12)
UPC	78678829080

Physical

Bus I/O	Micro-Change (M12)
Cable Connector Orientation	Straight
Cable Length	2.0m
Home Run Cable Length	2.0m
Home Run Connector	Mini-Change - 5 pole
Home Run Interface	Cable - Side Entry
Keyway	Single
LED Indicator	No
Material - Cable Jacket	PVC
Material - Housing	PBT
Material - Metal	Copper
Material - Plating Mating	Gold
Net Weight	294.835/g
Orientation	Top Mount
Poles	5
Poles (wired)	4
Ports	4
Temperature Range - Operating	-25°C to +90°C
Wiring Configuration	Single I/O per Port

Electrical


Current - Maximum per Contact	4.0A per port
Functional Wiring	Parallel
Voltage - Maximum	10-30V DC

Material Info

Engineering Number	DND4300-02
--------------------	------------

Reference - Drawing Numbers

Sales Drawing	SD-130037-002
---------------	---------------

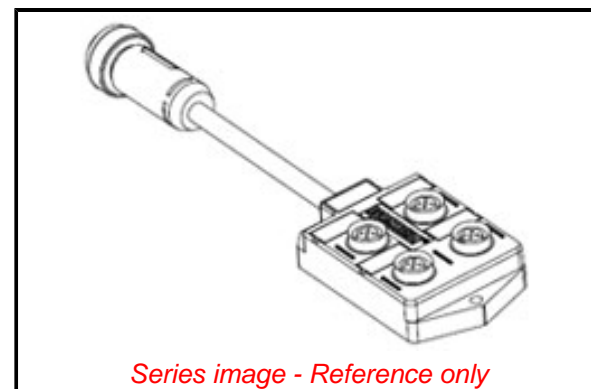

Series image - Reference only

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

China RoHS

Search Parts in this Series

[130037 Series](#)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[1300370005](#)