

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1300390236](#)
Status: **Active**
Overview: [Brad Mini-Change Connectors](#)
Description: Micro-Change (M12) Receptacle to DeviceNet D-Net Open with Screws, 5 Poles, Male (Straight) to Female (Straight), 5 Poles, PVC Cable, 5.0m (16.40') Length

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA LR6837

General

Product Family Industrial Cordsets
 Series [130039](#)
 Connector End A Micro-Change (M12)
 Connector End B D-Net Open
 IP Rating IP67
 Material - Contact Copper Alloy
 Overview [Brad Mini-Change Connectors](#)
 Product Name DeviceNet, Micro-Change (M12)
 Region Europe
 Type Double Ended
 UPC 78678887213

Physical

Cable Diameter N/A
 Cable Length 5.0m (16.40')
 Color - Cable Jacket Gray
 Coupling Style Threaded
 Gender Female-Male
 Keyway Single
 LED Indicator No
 Material - Cable Jacket PVC
 Material - Connector Body PVC
 Material - Coupling Nut N/A
 Material - Plating Mating Gold
 Orientation Straight to Straight
 Poles 5
 Temperature Range - Operating -20° to +80°C
 Wire Size AWG 22
 Wire/Cable Type E152210

Electrical


Current - Maximum per Contact 4.0A
 Voltage - Maximum 250V AC

Material Info

Engineering Number DNDC304-M050

Reference - Drawing Numbers

Sales Drawing SD-130039-029-001

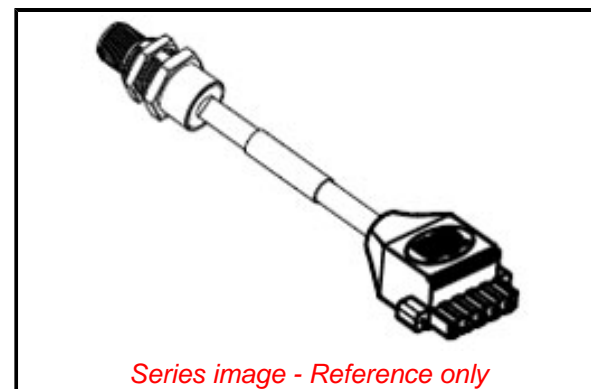

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

Search Parts in this Series

[130039 Series](#)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[1300390236](#)