

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [1300390312](#)  
**Status:** **Active**  
**Overview:** [Brad Mini-Change Connectors](#)  
**Description:** DeviceNet Mini-Change Receptacle, 5 Poles, Female (Straight) to DeviceNet Trunk Cable, 1/2 - 14 NPT Threads, 1.0m (3.28') Length

**Documents:**

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

**Agency Certification**

CSA LR6837  
 UL E152210

**General**

Product Family Industrial Receptacles  
 Series [130039](#)  
 IP Rating IP67  
 NEMA Rating NEMA 6  
 Overview [Brad Mini-Change Connectors](#)  
 Product Name DeviceNet Trunk, Mini-Change  
 Type Single Ended (pigtail)  
 UPC 78678832663

**Physical**

Coupling Type Internal Thread  
 Gender Female  
 Keyway Single  
 Length 1.0m  
 Material - Component Gray Anodized Aluminum  
 Mounting Thread Size 1/2" - 14 NPT  
 Orientation Straight  
 Panel Mount Front  
 Poles 5  
 Temperature Range - Operating -20° to +80°C  
 Wire Size AWG N/A  
 Wire/Cable Type N/A

**Electrical**


Current - Maximum per Contact 4.0A  
 Voltage - Maximum 300V AC/DC

**Material Info**

Engineering Number DNB5000-M010

**Reference - Drawing Numbers**

Sales Drawing SD-130039-003-001

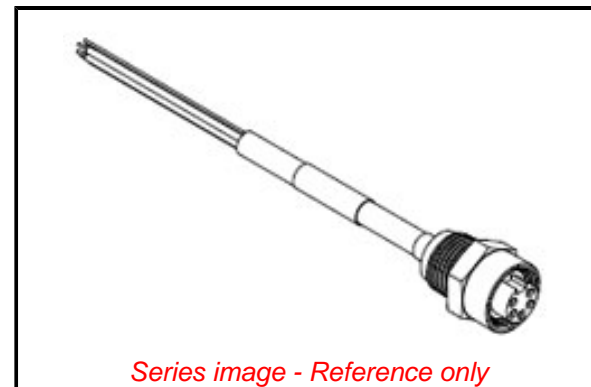

*Series image - Reference only*

**EU ELV**

**Not Reviewed**

**EU RoHS**

**Not Reviewed**

**REACH SVHC**

Not Reviewed

**Halogen-Free**

**Status**

**Not Reviewed**

For more information, please visit [Contact US](#)

China ROHS Not Reviewed

ELV Not Reviewed

RoHS Phthalates Not Reviewed

**Search Parts in this Series**

[130039 Series](#)

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[1300390312](#)