

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1300390317](#)
Status: **Active**
Overview: [Brad Mini-Change Connectors](#)
Description: DeviceNet Mini-Change Receptacle, 5 Poles, Male (Straight) with DeviceNet Mid Trunk Cable, 1/2 - 14 NPT Threads, 0.050m (1.97") Length

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA LR6837
 UL E152210

General

Product Family Industrial Receptacles
 Series [130039](#)
 IP Rating IP67
 NEMA Rating NEMA 6
 Overview [Brad Mini-Change Connectors](#)
 Product Name DeviceNet Trunk, Mini-Change
 Type Single Ended (pigtail)
 UPC 78678886577

Physical

Coupling Type External Thread
 Gender Male
 Keyway Single
 Length 0.050m
 Material - Component Gray Anodized Aluminum
 Mounting Thread Size 1/2" - 14 NPT
 Orientation Straight
 Panel Mount Front
 Poles 5
 Temperature Range - Operating -20° to +80°C
 Wire Size AWG 16, 20
 Wire/Cable Type Mid Cable

Electrical


Current - Maximum per Contact 4.0A
 Voltage - Maximum 300V AC/DC

Material Info

Engineering Number DNB5100-M005

Reference - Drawing Numbers

Sales Drawing SD-130039-004-001

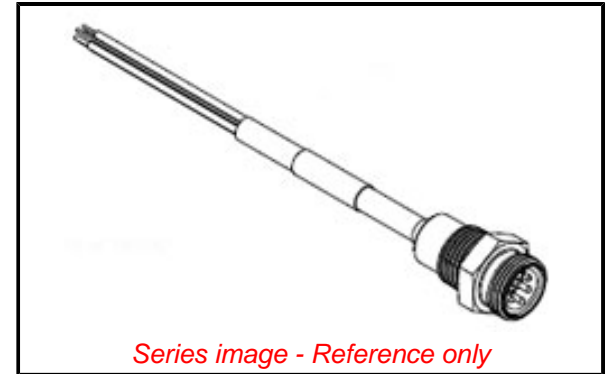

Series image - Reference only

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

Search Parts in this Series

[130039 Series](#)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[1300390317](#)