

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [1300390341](#)  
**Status:** **Active**  
**Overview:** [DeviceNet Solutions](#)  
**Description:** Mini-Change 5 Pole Tee Adapter, DeviceNet Female to Male

**Documents:**

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

**Agency Certification**

CSA LR6837  
 UL E152210

**General**

Product Family Industrial Tees and Splitters  
 Series [130039](#)  
 IP Rating IP67  
 Overview [DeviceNet Solutions](#)  
 Product Name DeviceNet Trunk  
 Type Drop Tee  
 UPC 78678849469

**Physical**

Color - Cable Jacket Gray  
 Drop Connector Micro-Change (M12)  
 Drop Gender Female  
 Keyway Single  
 LED Indicator No  
 Left Trunk Connector Mini-Change  
 Left Trunk Gender Female  
 Leg 1 Length N/A  
 Leg 2 Length N/A  
 Material - Cable Jacket N/A  
 Material - Connector Body Nylon, TPE  
 Material - Coupling Nut Die-Cast Zinc  
 Net Weight 65.650/g  
 Poles 5  
 Right Trunk Connector Mini-Change  
 Right Trunk Gender Male  
 Temperature Range - Operating -20°C to +80°C

**Electrical**


Current - Maximum per Contact 4.0A  
 Voltage - Maximum 250V AC/DC

**Material Info**

Engineering Number DND3020

**Reference - Drawing Numbers**

Sales Drawing 1300390341-000

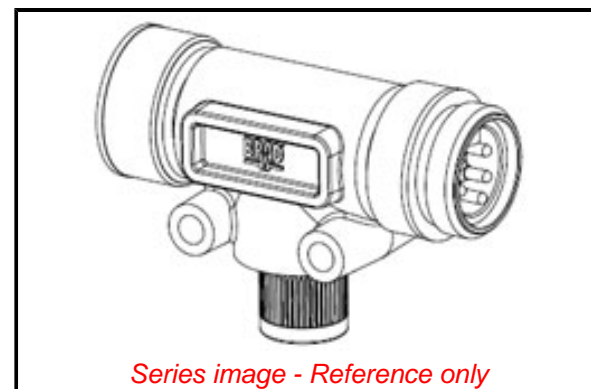

**EU ELV**

**Not Relevant**

**EU RoHS**

**Compliant with Exemption 6(c)**

**REACH SVHC**

Contained Per - D(2020)9139-DC (19 Jan 2021)

Lead

**Halogen-Free**

**Status**

**Not Low-Halogen**

For more information, please visit [Contact US](#)

China ROHS

50 Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

**Search Parts in this Series**

[130039](#) Series

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[1300390341](#)