

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1300420024](#)

Status: **Active**

Overview: [Brad Micro-Change \(M12\) Connectors](#)

Description: Micro-Change (M12) Single-Ended Cordset, 4 Poles, Female Straight to Pigtail, 2.0m (6.56') Length, Nickel (Ni) Plated Brass Coupler, Shielded PVC Cable

Documents:

[Drawing \(PDF\)](#)

[RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family	Industrial Cordsets
Series	130042
Connector End A	Micro-Change (M12)
Connector End B	Pigtail
IP Rating	IP67
Material - Contact	Copper Alloy
Overview	Brad Micro-Change (M12) Connectors
Product Name	Micro-Change (M12)
Protocol	N/A
Region	America, Asia, Europe
Type	Single Ended
UPC	78172504890

Physical

Cable Diameter	7.37mm (.290")
Cable Length	2.0m (6.56')
Color - Cable Jacket	Orange
Coupling Style	Threaded
Gender	Female-Pigtail
Keyway	Single
LED Indicator	No
Material - Cable Jacket	PVC
Material - Connector Body	PVC
Material - Coupling Nut	Nickel-plated Brass
Material - Plating Mating	Gold
Orientation	Straight to Pigtail
Poles	4
Temperature Range - Operating	-40° to +105°C
Wire Size AWG	18
Wire/Cable Type	N/A

Electrical


Current - Maximum per Contact	4.0A
Voltage - Maximum	250V

Material Info

Engineering Number 804000D09M020

Reference - Drawing Numbers

Sales Drawing SD-130042-001-001

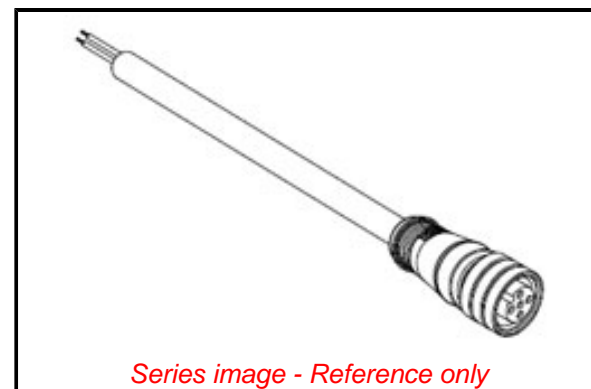

Series image - Reference only

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS Not Reviewed

ELV Not Reviewed

RoHS Phthalates Not Reviewed

Search Parts in this Series

[130042 Series](#)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[1300420024](#)