

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [1300478011](#)  
**Status:** **Active**  
**Overview:** [Brad Industrial Ethernet Solutions](#)  
**Description:** Brad RJ-45 Field Attachable Connector, 8 Poles, Right-Angle, Male, Shielded, IDC Termination, AWG 26-24

**Documents:**

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)  
[Datasheet \(PDF\)](#)

**Agency Certification**

UL E361772

**General**

Product Family Field Attachable / Accessories  
 Series [130047](#)  
 Approvals cCSAus certified  
 Comments POE+ according to IEEE 802.3AT  
 Communication Speed 10-Gigabit Ethernet  
 IP Rating IP20  
 Material - Contact Brass  
 Overview [Brad Industrial Ethernet Solutions](#)  
 Product Name RJ45 Cat6A  
 Type Field Attachable Connector  
 UPC 889056623278

**Physical**

Cable Diameter 5.50-10.00mm (.216-.393")  
 Coupling Type Push to Lock  
 Diagnostics / LEDs No  
 Diagnostics Port No  
 Gender Male  
 Keyway X-coded  
 Material - Connector Body Zinc Die-Cast with Nickel  
 Material - Coupling Nut Clear UL 94 V0  
 Material - Plating Mating Gold  
 Net Weight 22.582/g  
 Orientation 90° Angle  
 Poles 8  
 Temperature Range - Operating -40°C to +85°C  
 Wire Size AWG 26-24/1

**Electrical**


Current - Maximum per Contact 0.5A  
 Voltage - Maximum 48V

**Material Info**

Engineering Number E6AS07-6

**Reference - Drawing Numbers**

Sales Drawing 1300478009-000

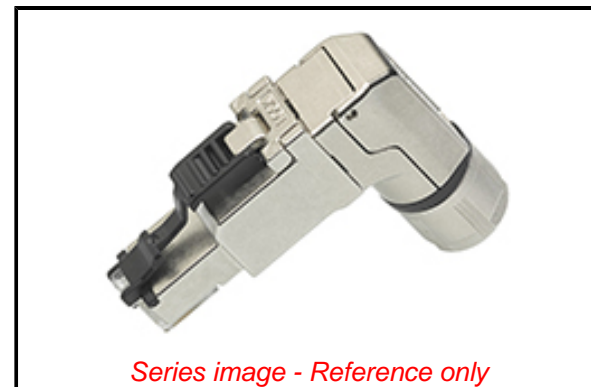

*Series image - Reference only*

**EU ELV**

**Not Relevant**

**EU RoHS**

**Compliant**

**REACH SVHC**

Not Contained Per -  
 D(2021)4569-DC (8  
 July 2021)

**Halogen-Free**

**Status**

**Low-Halogen**

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

Green Image

Not Relevant

Not Contained

**Search Parts in this Series**

[130047 Series](#)

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[130047-8011](#)