

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [1300540013](#)  
**Status:** **Active**  
**Overview:** Brad Industrial Ethernet Solutions  
**Description:** Ultra-Lock (M12) Single-Ended Receptacle, 4 Poles, Female (Straight) to Pigtail, 2.0m (6.56') Length

**Documents:**

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

**Agency Certification**

UL E200650

**General**

Product Family Industrial Cordsets  
 Series [130054](#)  
 Connector End A Ultra-Lock (M12)  
 Connector End B Pigtail  
 IP Rating IP67  
 Material - Contact Copper Alloy  
 Overview [Brad Industrial Ethernet Solutions](#)  
 Performance Category 5e  
 Product Name Ultra-Lock (M12)  
 Protocol N/A  
 Type Single Ended  
 UPC 78678804778

**Physical**

Cable Diameter N/A  
 Cable Length 2.0m (6.56')  
 Color - Cable Jacket Teal  
 Coupling Style Threaded  
 Gender Female-Pigtail  
 Keyway D-coded  
 LED Indicator No  
 Material - Cable Jacket PVC  
 Material - Connector Body PVC  
 Material - Coupling Nut Nickel-plated Brass  
 Material - Plating Mating Gold  
 Net Weight 103.831/g  
 Orientation Straight to Pigtail  
 Poles 4  
 Temperature Range - Operating -25°C to +75°C  
 Wire Size AWG 24  
 Wire/Cable Type E152210

**Electrical**


Current - Maximum per Contact 1.5A  
 Voltage - Maximum 125V

**Material Info**

Engineering Number ERWAAJ4002M020

**Reference - Drawing Numbers**

Sales Drawing SD-130054-001-001

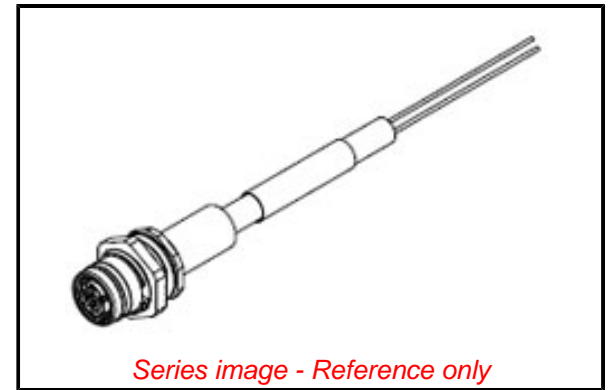

*Series image - Reference only*

**EU ELV**

**Not Relevant**

**EU RoHS**

**Compliant with Exemption 6(c)**

**REACH SVHC**

Contained Per - D(2020)9139-DC (19 Jan 2021)

Lead

**Halogen-Free**

**Status**

**Not Low-Halogen**

For more information, please visit [Contact US](#)

China ROHS

50 Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

**Search Parts in this Series**

[130054 Series](#)

**PLEASE CHECK [WWW.MOLEX.COM](http://WWW.MOLEX.COM) FOR LATEST PART INFORMATION**

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[130054-0013](#)