

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [1300640401](#)

**Status:** **Active**

**Overview:** [BradPower Cordsets and Receptacles](#)

**Description:** BradPower D-Size (1 3/8"-M35) Double-Ended Cordset, 3 Poles, Female (Straight) to Male (Straight) with Alternate Key, 10 AWG, PVC Cable, 2.0m (6.56') Length

**Documents:**

[Drawing \(PDF\)](#)

[RoHS Certificate of Compliance \(PDF\)](#)

**Agency Certification**

UL E258922

**General**

Product Family	Industrial Cordsets
Series	<a href="#">130064</a>
Connector End A	BradPower D-Size (1 3/8"-M35)
Connector End B	BradPower D-Size (1 3/8"-M35)
IP Rating	IP67
Material - Contact	Copper Alloy
Overview	<a href="#">BradPower Cordsets and Receptacles</a>
Product Name	BradPower D-Size
Protocol	EtherNet
Region	Europe
Type	Double Ended
UPC	78172512560

**Physical**

Cable Diameter	4.90mm (.193")
Cable Length	2.0m (6.56')
Color - Cable Jacket	Gray
Coupling Style	Threaded
Gender	Female-Male
Keyway	Single
LED Indicator	No
Material - Cable Jacket	PVC
Material - Connector Body	PVC
Material - Coupling Nut	Anodized Aluminum
Material - Plating Mating	Gold
Orientation	Straight to Straight
Poles	3
Temperature Range - Operating	-20° to +105°C
Wire Size AWG	10
Wire/Cable Type	STOOW, TC-ER Direct Burial

**Electrical**


Current - Maximum per Contact	30.0A
Voltage - Maximum	600V

**Material Info**

Engineering Number CC3130A48M020

**Reference - Drawing Numbers**

Sales Drawing SD-130064-401-001

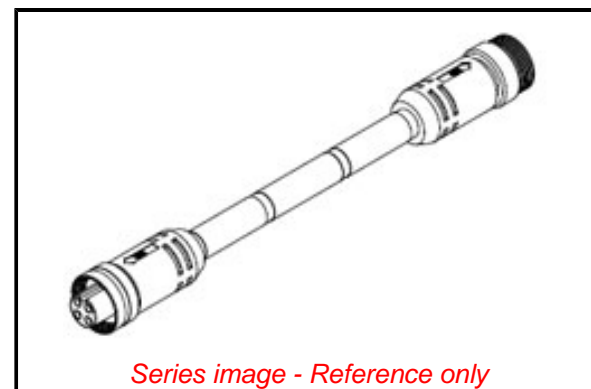

*Series image - Reference only*

**EU ELV**

**Not Relevant**

**EU RoHS**

**Not Reviewed**

**REACH SVHC**

Not Reviewed

**Halogen-Free**

**Status**

**Not Reviewed**

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Relevant

RoHS Phthalates

Not Reviewed

**Search Parts in this Series**

[130064 Series](#)

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[1300640401](#)