

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1300660159](#)
Status: **Active**
Overview: [BradPower Cordsets and Receptacles](#)
Description: BradPower D-Size (1 3/8"-M35) Female, 1/2" NPT 2, 4 Poles, Receptacle, Female (Straight) to 10 AWG Leads, 1.70m (5.58') Length

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

UL E258922

General

Product Family Industrial Receptacles
 Series [130066](#)
 IP Rating IP67
 Overview [BradPower Cordsets and Receptacles](#)
 Product Name BradPower D-Size
 Type Single Ended (pigtail)
 UPC 78678881522

Physical

Coupling Type Internal Thread
 Gender Female
 Keyway Single
 Length 1.70m
 Material - Component Black Anodized Aluminum
 Mounting Thread Size 1/2" NPT
 Orientation Straight
 Panel Mount Back, Front
 Poles 4
 Temperature Range - Operating 0° to +105°C
 Wire Size AWG 10
 Wire/Cable Type N/A

Electrical


Current - Maximum per Contact 25.0A
 Voltage - Maximum 600V

Material Info

Engineering Number CR4000A30M017

Reference - Drawing Numbers

Sales Drawing SD-130066-025-001

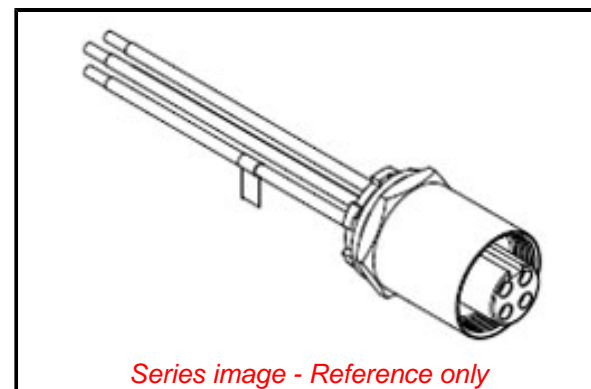

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

Not Relevant

ELV

Not Relevant

RoHS Phthalates

Not Reviewed

Search Parts in this Series

[130066 Series](#)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[1300660159](#)