

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1300660281](#)
Status: **Active**
Overview: BradPower Cordsets and Receptacles
Description: BradPower A-Size (7/8"-M22) Receptacle, 3 Poles, 1/2" - 14 NPT, Female, (Straight) to 16/1 AWG, 0.5m (19.7") Length

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family	Industrial Receptacles
Series	130066
IP Rating	IP67
Overview	BradPower Cordsets and Receptacles
Product Name	BradPower A-Size
Type	Single Ended (pigtail)
UPC	78172513914

Physical


Coupling Type	Internal Thread
Gender	Female
Keyway	Single
Length	0.50m
Material - Component	Black Anodized Aluminum
Mounting Thread Size	1/2" - 14 NPT
Orientation	Straight
Panel Mount	Front
Poles	3
Temperature Range - Operating	-20° to +105°C
Wire Size AWG	16
Wire/Cable Type	UL 2237

Electrical

Current - Maximum per Contact	13.0A
Voltage - Maximum	600V AC/DC

Material Info

Engineering Number	1R3000A20M005G
--------------------	----------------

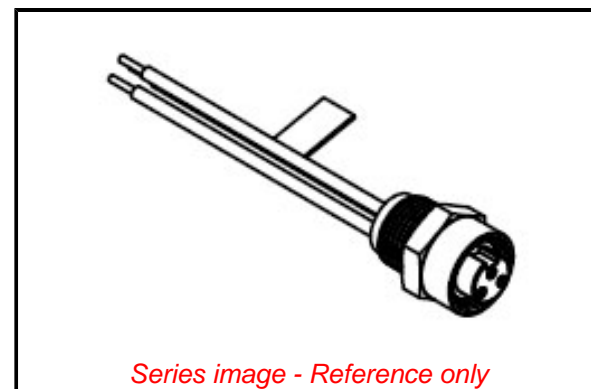

EU ELV

Not Relevant

EU RoHS

Compliant with Exemption 6(c)

REACH SVHC

Contained Per -
D(2020)9139-DC (19
Jan 2021)
Lead

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

ZZCERT_CE -

Declaration of

Conformity

China RoHS

Not Relevant

Not Relevant

Not Contained

CER_4000380991_00_000.pdf

Search Parts in this Series

[130066 Series](#)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[1300660281](#)