

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [1300920166](#)  
**Status:** **Active**  
**Overview:** [Slip Rings](#)  
**Description:** Aero-Motive Self-Contained Slip Ring, 21A, 12 AWG, 28 Conductors, Bore Size 38.10mm (1.500") Diameter

**Documents:**  
[RoHS Certificate of Compliance \(PDF\)](#)

**Agency Certification**


CSA LR29921

**General**

|                               |                            |
|-------------------------------|----------------------------|
| Product Family                | Slip Rings                 |
| Series                        | <a href="#">130092</a>     |
| Center Bore Diameter          | 38.10mm (1.500")           |
| Component Type                | Self-Contained             |
| Current - Maximum per Contact | 21.0A                      |
| Mounting Style                | Horizontal                 |
| Number of Conductors          | 28                         |
| Overview                      | <a href="#">Slip Rings</a> |
| Packaging Type                | Carton                     |
| Product Name                  | Aero-Motive                |
| Speed (RPM)                   | Continuous 125             |
| Temperature Range - Operating | -40°C to +120°C            |
| UPC                           | 78678867808                |
| Voltage - Maximum             | 600V                       |
| Wire Size AWG                 | 12                         |

**Material Info**

Engineering Number SR328

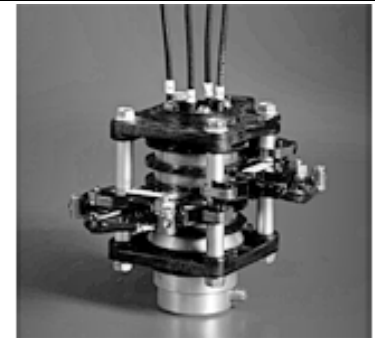

*Series image - Reference only*

**EU ELV**

**Not Reviewed**

**EU RoHS**

**Not Reviewed**

**REACH SVHC**

Not Reviewed

**Halogen-Free**

**Status**

**Not Reviewed**

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

**Search Parts in this Series**

[130092 Series](#)

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[1300920166](#)