

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [1300940292](#)  
**Status:** **Active**  
**Overview:** [Support Grips](#)  
**Description:** Standard Duty Support Grip, Double Eye, Split Lace, Single Weave, Cable Diameter 19.05-25.15mm (.750-.990"), Approximate Break Strength 598.74kg (1320 lbs)

**Documents:**

[Brochure \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

**Agency Certification**


CSA LR32159

**General**

Product Family	Cable Grips
Series	<a href="#">130094</a>
Eye Type	Double
O-Ring	N/A
Overview	<a href="#">Support Grips</a>
Product Name	Standard Duty
Type	Support Grip
UPC	78678835137
<b>Physical</b>	
Approximate Break Strength	598.74kg (1320 lbs)
Bale Length	0.102m (4.00")
Body Style	Straight
Cable Diameter	19.05-25.15mm (.750-.990")
Color - Grommet	N/A
Gender	N/A
Material - Body	N/A
Material - Grip	Non-magnetic Tin Bronze Wire
Mesh Length	0.356m (14.00")
Number of Holes	N/A
Thread Size	N/A

**Material Info**

Engineering Number 35137

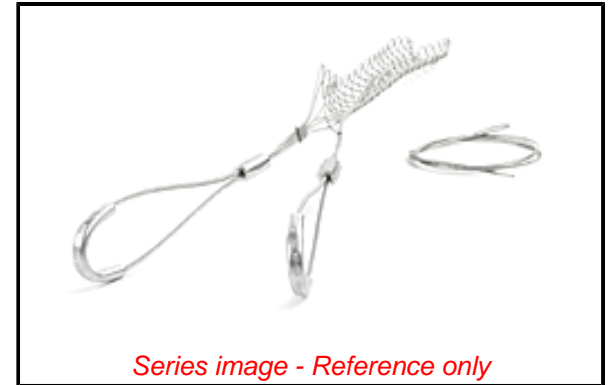

**EU ELV**

**Not Reviewed**

**EU RoHS**

**Not Reviewed**

**REACH SVHC**

Not Reviewed

**Halogen-Free**

**Status**

**Not Reviewed**

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

**Search Parts in this Series**

[130094](#) Series

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[1300940292](#)