

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1300940299](#)
Status: **Active**
Overview: [Support Grips](#)
Description: Standard Duty Support Grip, Double Eye, Split Lace, Single Weave, Cable Diameter 38.10-44.20mm (1.500-1.740"), Approximate Break Strength 870.90kg (1920 lbs), Stainless Steel

Documents:
[RoHS Certificate of Compliance \(PDF\)](#)

General


Product Family	Cable Grips
Series	130094
Eye Type	Double
NEMA Rating	NEMA 4
O-Ring	No
Overview	Support Grips
Product Name	Standard Duty
Type	Support Grip
UPC	78678809815

Physical

Approximate Break Strength	870.90kg (1920 lbs)
Bale Length	0.152m (6.00")
Body Style	Straight
Cable Diameter	38.10-44.20mm (1.500-1.740")
Color - Grommet	N/A
Gender	N/A
Material - Body	N/A
Material - Grip	Stainless Steel
Mesh Length	0.432m (17.00")
Number of Holes	N/A
Thread Size	N/A

Material Info

Engineering Number	35140SS
--------------------	---------

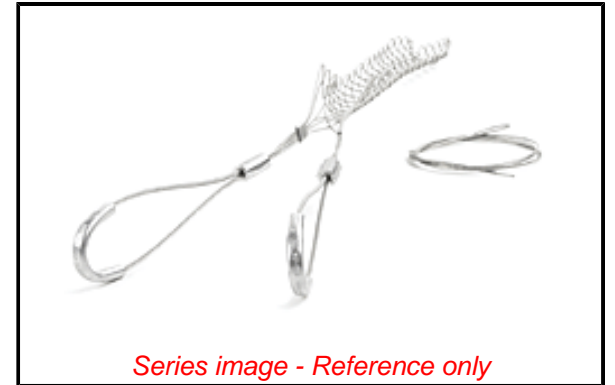

Series image - Reference only

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

Search Parts in this Series

[130094](#) Series

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[1300940299](#)