

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1300940335](#)
Status: **Active**
Overview: [Support Grips](#)
Description: Standard Duty Support Grip, Offset Eye, Split Lace, Single Weave, Cable Diameter 19.05-25.15mm (.750-.990"), Approximate Break Strength 435.45kg (960 lbs), Stainless Steel

Documents:
[RoHS Certificate of Compliance \(PDF\)](#)

General


Product Family	Cable Grips
Series	130094
Eye Type	Offset
NEMA Rating	NEMA 4
O-Ring	No
Overview	Support Grips
Product Name	Standard Duty
Type	Support Grip
UPC	78678809834

Physical

Approximate Break Strength	435.45kg (960 lbs)
Bale Length	0.102m (4.00")
Body Style	Straight
Cable Diameter	19.05-25.15mm (.750-.990")
Color - Grommet	N/A
Gender	N/A
Material - Body	N/A
Material - Grip	Stainless Steel
Mesh Length	0.356m (14.00")
Number of Holes	N/A
Thread Size	N/A

Material Info

Engineering Number	35197SS
--------------------	---------

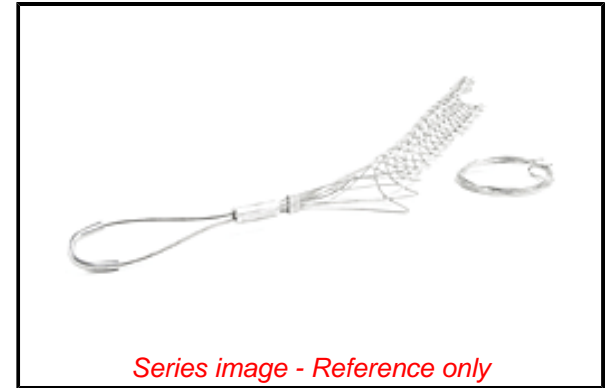

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

Search Parts in this Series

[130094](#) Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[1300940335](#)