

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1300940357](#)
Status: **Active**
Overview: [Support Grips](#)
Description: Standard Duty Support Grip, Locking Bale, Split Lace, Single Weave, Cable Diameter 25.40-31.50mm (1.000-1.240") Approximate Break Strength, Approximate Break Strength 870.90kg (1920 lbs)

Documents:

[Brochure \(PDF\)](#)

[RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification


CSA LR32159

General

Product Family	Cable Grips
Series	130094
Eye Type	Locking Bale
O-Ring	N/A
Overview	Support Grips
Product Name	Standard Duty
Type	Support Grip
UPC	78678835228
Physical	
Approximate Break Strength	870.90kg (1920 lbs)
Bale Length	0.457m (18.00")
Body Style	Straight
Cable Diameter	25.40-31.50mm (1.000-1.240")
Color - Grommet	N/A
Gender	N/A
Material - Body	N/A
Material - Grip	Non-magnetic Tin Bronze Wire
Mesh Length	0.38m (15.00")
Number of Holes	N/A
Thread Size	N/A

Material Info

Engineering Number 35228

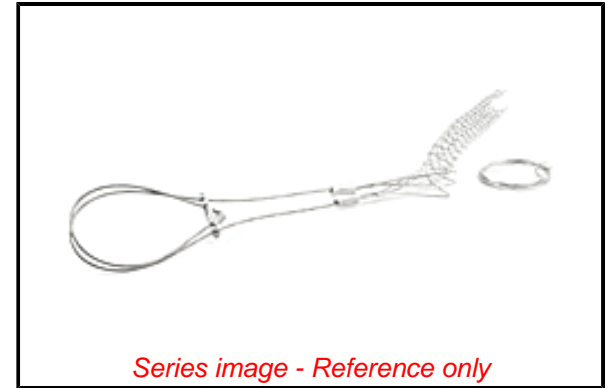

Series image - Reference only

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

Search Parts in this Series

[130094](#) Series

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[1300940357](#)