

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1300940379](#)
Status: **Active**
Overview: [Support Grips](#)
Description: Standard Duty Support Grip, Double "U" Eye, Split Rod, Single Weave, Cable Diameter 44.45-50.55mm (1.750-1.990"), Approximate Break Strength 1428.82kg (3150 lbs), Stainless Steel

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family	Cable Grips
Series	130094
Eye Type	Double
NEMA Rating	NEMA 4
O-Ring	No
Overview	Support Grips
Product Name	Standard Duty
Type	Support Grip
UPC	78678809885

Physical


Approximate Break Strength	1428.82kg (3150 lbs)
Bale Length	0.152m (6.00")
Body Style	Straight
Cable Diameter	44.45-50.55mm (1.750-1.990")
Color - Grommet	N/A
Gender	N/A
Material - Body	N/A
Material - Grip	Stainless Steel
Mesh Length	0.508m (20.00")
Number of Holes	N/A
Thread Size	N/A

Material Info

Engineering Number	35276SS
--------------------	---------

Reference - Drawing Numbers

Sales Drawing	SD-130094-044
---------------	---------------

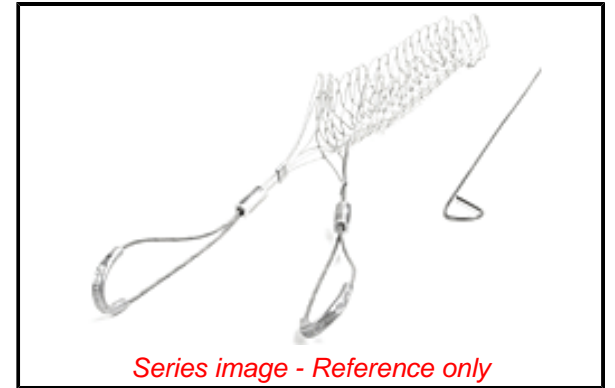

Series image - Reference only

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

Search Parts in this Series

[130094 Series](#)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[1300940379](#)