

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1300940384](#)
Status: **Active**
Overview: [Support Grips](#)
Description: Standard Duty Support Grip, Double "U" Eye, Split Rod, Single Weave, Cable Diameter 88.90-101.35m (3.500-3.990"), Approximate Break Strength 2394.97kg (5280 lbs)

Documents:

[Brochure \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification


CSA LR32159

General

| | |
|----------------------------|-------------------------------|
| Product Family | Cable Grips |
| Series | 130094 |
| Eye Type | Double |
| O-Ring | N/A |
| Overview | Support Grips |
| Product Name | Standard Duty |
| Type | Support Grip |
| UPC | 78678835280 |
| Physical | |
| Approximate Break Strength | 2394.97kg (5280 lbs) |
| Bale Length | 0.203m (8.00") |
| Body Style | Straight |
| Cable Diameter | 88.90-101.35mm (3.500-3.990") |
| Color - Grommet | N/A |
| Gender | N/A |
| Material - Body | N/A |
| Material - Grip | Non-magnetic Tin Bronze Wire |
| Mesh Length | 0.711m (28.00") |
| Number of Holes | N/A |
| Thread Size | N/A |

Material Info

Engineering Number 35280

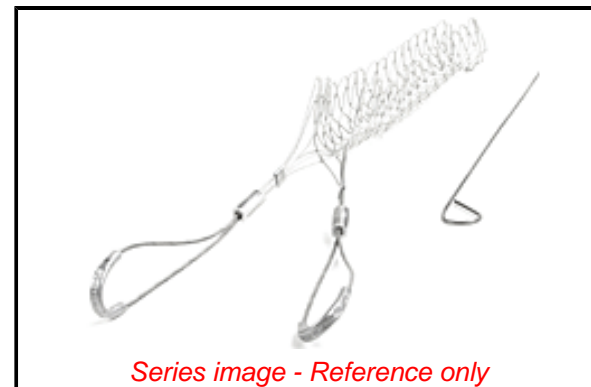

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

Search Parts in this Series

[130094](#) Series

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[1300940384](#)