

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1300940389](#)
Status: **Active**
Overview: [Support Grips](#)
Description: Standard Duty Support Grip, Single "U" Eye, Split Rod, Single Weave, Cable Diameter 19.05-25.15mm (.750-.990"), Approximate Break Strength 598.74kg (1320 lbs)

Documents:

[Brochure \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification


CSA LR32159

General

Product Family	Cable Grips
Series	130094
Eye Type	Single
O-Ring	N/A
Overview	Support Grips
Product Name	Standard Duty
Type	Support Grip
UPC	78678835287
Physical	
Approximate Break Strength	598.74kg (1320 lbs)
Bale Length	0.203m (8.00")
Body Style	Straight
Cable Diameter	19.05-25.15mm (.750-.990")
Color - Grommet	N/A
Gender	N/A
Material - Body	N/A
Material - Grip	Non-magnetic Tin Bronze Wire
Mesh Length	0.356m (14.00")
Number of Holes	N/A
Thread Size	N/A

Material Info

Engineering Number 35287

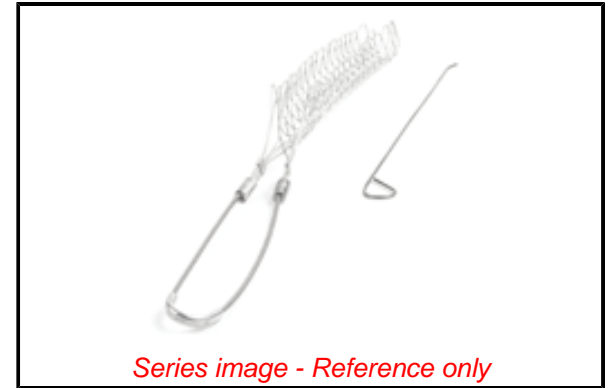

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Not Relevant

Not Contained

Search Parts in this Series

[130094](#) Series

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[1300940389](#)