

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [1300940395](#)  
**Status:** **Active**  
**Overview:** [Support Grips](#)  
**Description:** Standard Duty Support Grip, Single "U" Eye, Split Rod, Single Weave, Cable Diameter 38.10-44.20mm (1.500-1.740"), Approximate Break Strength 762.04kg (1680 lbs)

**Documents:**

[Brochure \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

**Agency Certification**


CSA LR32159

**General**

Product Family	Cable Grips
Series	<a href="#">130094</a>
Eye Type	Single
O-Ring	N/A
Overview	<a href="#">Support Grips</a>
Product Name	Standard Duty
Type	Support Grip
UPC	78678835290
<b>Physical</b>	
Approximate Break Strength	762.04kg (1680 lbs)
Bale Length	0.305m (12.00")
Body Style	Straight
Cable Diameter	38.10-44.20mm (1.500-1.740")
Color - Grommet	N/A
Gender	N/A
Material - Body	N/A
Material - Grip	Non-magnetic Tin Bronze Wire
Mesh Length	0.432m (17.00")
Number of Holes	N/A
Thread Size	N/A

**Material Info**

Engineering Number 35290

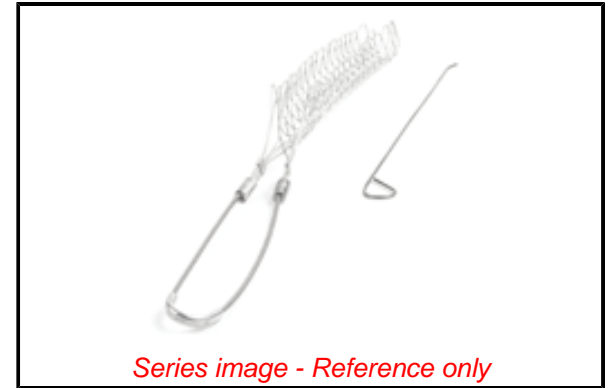

**EU ELV**

**Not Reviewed**

**EU RoHS**

**Not Reviewed**

**REACH SVHC**

Not Reviewed

**Halogen-Free**

**Status**

**Not Reviewed**

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

**Search Parts in this Series**

[130094](#) Series

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[1300940395](#)