

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [1300940421](#)  
**Status:** **Active**  
**Overview:** [Support Grips](#)  
**Description:** Standard Duty Support Grip, Offset Eye, Split Rod, Single Weave, Cable Diameter 50.80-63.25mm (2.000-2.490"), Approximate Break Strength 1524.07kg (3360 lbs), Stainless Steel

**Documents:**  
[RoHS Certificate of Compliance \(PDF\)](#)

**General**


Product Family	Cable Grips
Series	<a href="#">130094</a>
Eye Type	Offset
NEMA Rating	NEMA 4
O-Ring	No
Overview	<a href="#">Support Grips</a>
Product Name	Standard Duty
Type	Support Grip
UPC	78678809906

**Physical**

Approximate Break Strength	1524.07kg (3360 lbs)
Bale Length	0.152m (6.00")
Body Style	Straight
Cable Diameter	50.80-63.25mm (2.000-2.490")
Color - Grommet	N/A
Gender	N/A
Material - Body	N/A
Material - Grip	Stainless Steel
Mesh Length	0.559m (22.00")
Number of Holes	N/A
Thread Size	N/A

**Material Info**

Engineering Number	35307SS
--------------------	---------

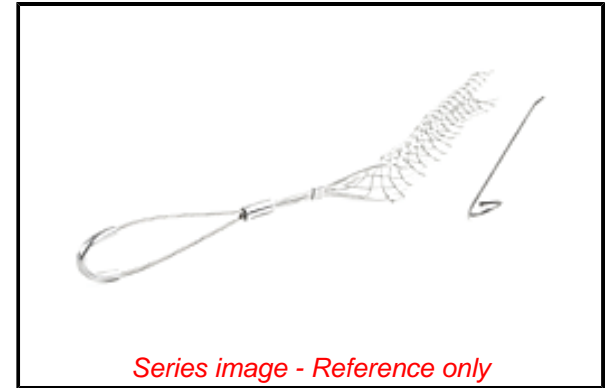

**EU ELV**

**Not Reviewed**

**EU RoHS**

**Not Reviewed**

**REACH SVHC**

Not Reviewed

**Halogen-Free**

**Status**

**Not Reviewed**

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

**Search Parts in this Series**

[130094](#) Series

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[1300940421](#)