

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1300940424](#)
Status: **Active**
Overview: [Support Grips](#)
Description: Standard Duty Support Grip, Offset Eye, Split Rod, Single Weave, Cable Diameter 76.20-88.65mm (3.000-3.490"), Approximate Break Strength 2286.11kg (5040 lbs)

Documents:

[Brochure \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification


CSA LR32159

General

Product Family	Cable Grips
Series	130094
Eye Type	Offset
O-Ring	N/A
Overview	Support Grips
Product Name	Standard Duty
Type	Support Grip
UPC	78678835309
Physical	
Approximate Break Strength	2286.11kg (5040 lbs)
Bale Length	0.102m (4.00")
Body Style	Straight
Cable Diameter	76.20-88.65mm (3.000-3.490")
Color - Grommet	N/A
Gender	N/A
Material - Body	N/A
Material - Grip	Non-magnetic Tin Bronze Wire
Mesh Length	0.66m (26.00")
Number of Holes	N/A
Thread Size	N/A

Material Info

Engineering Number 35309

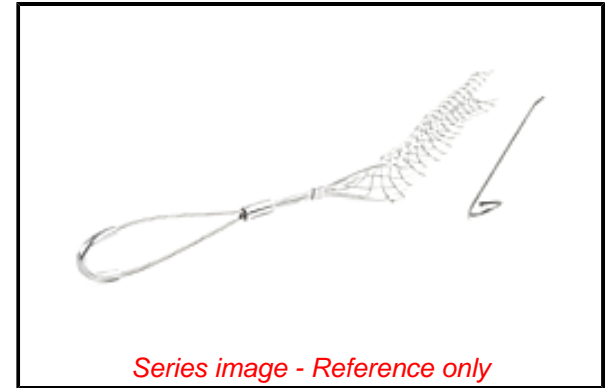

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

Search Parts in this Series

[130094](#) Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[1300940424](#)