

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [1300940427](#)  
**Status:** **Active**  
**Overview:** [Support Grips](#)  
**Description:** Standard Duty Support Grip, Offset Eye, Split Rod, Single Weave, Cable Diameter 88.90-101.35m (3.500-3.990"), Approximate Break Strength 2286.11kg (5040 lbs), Stainless Steel

**Documents:**  
[RoHS Certificate of Compliance \(PDF\)](#)

**General**


Product Family	Cable Grips
Series	<a href="#">130094</a>
Eye Type	Offset
NEMA Rating	NEMA 4
O-Ring	No
Overview	<a href="#">Support Grips</a>
Product Name	Standard Duty
Type	Support Grip
UPC	78678809915

**Physical**

Approximate Break Strength	2286.11kg (5040 lbs)
Bale Length	0.229m (9.00")
Body Style	Straight
Cable Diameter	88.90-101.35mm (3.500-3.990")
Color - Grommet	N/A
Gender	N/A
Material - Body	N/A
Material - Grip	Stainless Steel
Mesh Length	0.711m (28.00")
Number of Holes	N/A
Thread Size	N/A

**Material Info**

Engineering Number	35310SS
--------------------	---------

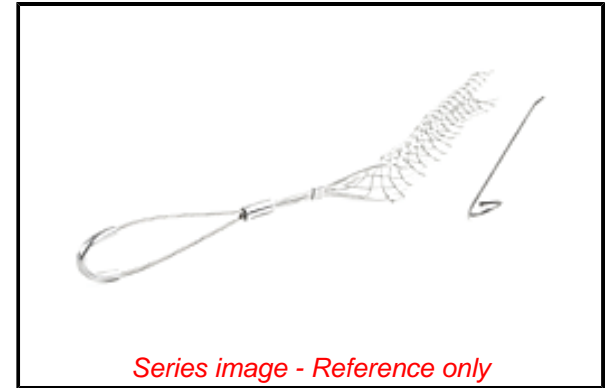

**EU ELV**

**Not Reviewed**

**EU RoHS**

**Not Reviewed**

**REACH SVHC**

Not Reviewed

**Halogen-Free**

**Status**

**Not Reviewed**

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

**Search Parts in this Series**

[130094](#) Series

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[1300940427](#)