

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1300940438](#)
Status: **Active**
Overview: [Support Grips](#)
Description: Standard Duty Support Grip, Locking Bale Eye, Split Rod, Single Weave, Cable Diameter 50.80-63.25mm (2.000-2.490"), Approximate Break Strength 1524.07kg (3360 lbs),

Documents:

[Brochure \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA LR32159

General


Product Family Cable Grips
 Series [130094](#)
 Eye Type Locking Bale
 O-Ring N/A
 Overview [Support Grips](#)
 Product Name Standard Duty
 Type Support Grip
 UPC 78678835337

Physical

Approximate Break Strength 1524.07kg (3360 lbs)
 Bale Length 0.457m (18.00")
 Body Style Straight
 Cable Diameter 50.80-63.25mm (2.000-2.490")
 Color - Grommet N/A
 Gender N/A
 Material - Body N/A
 Material - Grip Non-magnetic Tin Bronze Wire
 Mesh Length 0.559m (22.00")
 Number of Holes N/A
 Thread Size N/A

Material Info

Engineering Number 35337

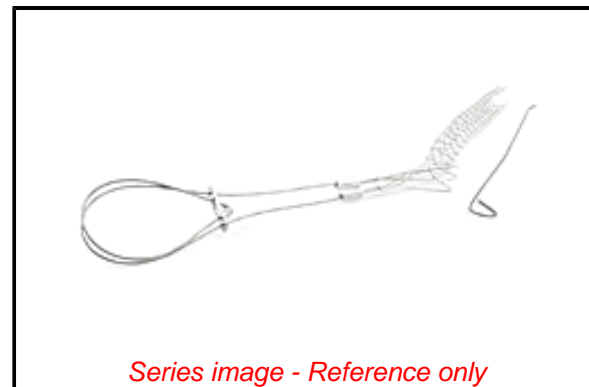

Series image - Reference only

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

Search Parts in this Series

[130094](#) Series

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[1300940438](#)