

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [1300940442](#)  
**Status:** **Active**  
**Overview:** [Support Grips](#)  
**Description:** Heavy Duty Support Grip, Double Eye, Double Weave, Closed Mesh, Cable Diameter 25.40-31.50mm (1.000-1.240"), Approximate Break Strength 2140.96kg (4720 lbs), Stainless Steel

**Documents:**

[Brochure \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

**Agency Certification**

CSA LR32159

**General**


Product Family Cable Grips  
 Series [130094](#)  
 Eye Type Double  
 O-Ring N/A  
 Overview [Support Grips](#)  
 Product Name Heavy Duty  
 Type Support Grip  
 UPC 78678835426

**Physical**

Approximate Break Strength 2140.96kg (4720 lbs)  
 Bale Length 0.254m (10.00")  
 Body Style Straight  
 Cable Diameter 25.40-31.50mm (1.000-1.240")  
 Color - Grommet N/A  
 Gender N/A  
 Material - Body N/A  
 Material - Grip Non-magnetic Tin Bronze Wire  
 Mesh Length 0.762m (30.00")  
 Number of Holes N/A  
 Thread Size N/A

**Material Info**

Engineering Number 35426

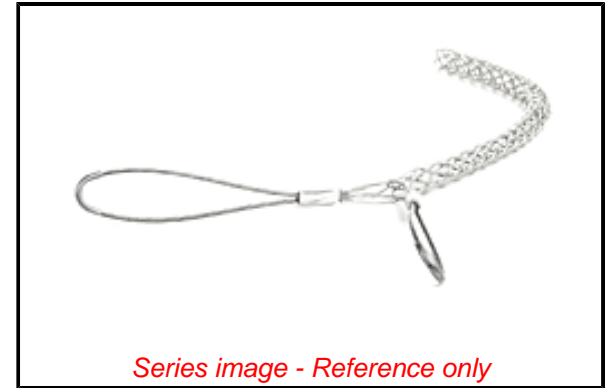

**EU ELV**

**Not Reviewed**

**EU RoHS**

**Not Reviewed**

**REACH SVHC**

Not Reviewed

**Halogen-Free**

**Status**

**Not Reviewed**

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

**Search Parts in this Series**

[130094](#) Series

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[1300940442](#)