

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1300940471](#)
Status: **Active**
Overview: [Support Grips](#)
Description: Heavy Duty Support Grip, Double Eye, Double Weave, Split Lace, Cable Diameter 38.10-50.55mm (1.500-1.990"), Approximate Break Strength 2131.88kg (4700 lbs), Stainless Steel

Documents:
[RoHS Certificate of Compliance \(PDF\)](#)

General


Product Family	Cable Grips
Series	130094
Eye Type	Double
NEMA Rating	NEMA 4
O-Ring	No
Overview	Support Grips
Product Name	Heavy Duty
Type	Support Grip
UPC	78678809939

Physical

Approximate Break Strength	2131.88kg (4700 lbs)
Bale Length	0.254m (10.00")
Body Style	Straight
Cable Diameter	38.10-50.55mm (1.500-1.990")
Color - Grommet	N/A
Gender	N/A
Material - Body	N/A
Material - Grip	Stainless Steel
Mesh Length	0.889m (35.00")
Number of Holes	N/A
Thread Size	N/A

Material Info

Engineering Number	35443SS
--------------------	---------

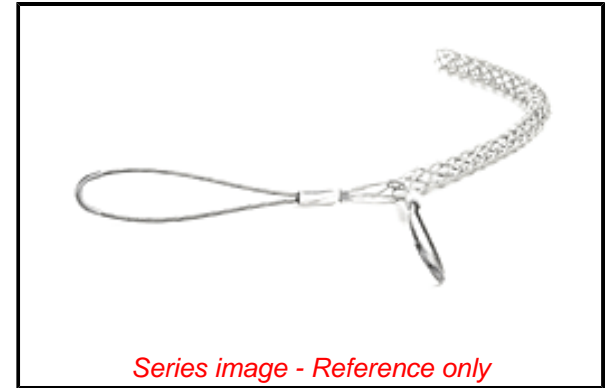

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

Search Parts in this Series

[130094](#) Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[1300940471](#)