

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1300940527](#)
Status: **Active**
Overview: [Support Grips](#)
Description: Support Grips for Fiber Optics, Closed Mesh, Single Eye, Bale Length 7", Cable Diameter 14.22-18.03mm (.560-.710"), Approximate Break Strength 272.16kg (600 lbs)

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Brochure \(PDF\)](#)

Agency Certification

CSA LR32159

General

Product Family	Cable Grips
Series	130094
Eye Type	Single
O-Ring	N/A
Overview	Support Grips
Product Name	Fiber Optic
Type	Support Grip
UPC	78678836675

Physical


Approximate Break Strength	272.16kg (600 lbs)
Bale Length	0.178m (7.00")
Body Style	Straight
Cable Diameter	14.22-18.03mm (.560-.710")
Color - Grommet	N/A
Gender	N/A
Material - Body	N/A
Material - Grip	Non-magnetic Tin Bronze Wire
Mesh Length	0.14m (5.50")
Number of Holes	N/A
Thread Size	N/A

Material Info

Engineering Number 36675

Reference - Drawing Numbers

Sales Drawing SD-130094-001

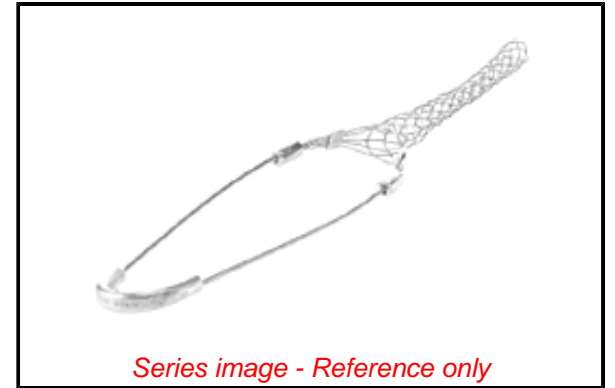

Series image - Reference only

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

Search Parts in this Series

[130094 Series](#)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[1300940527](#)