

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [1300940528](#)  
**Status:** **Active**  
**Overview:** [Support Grips](#)  
**Description:** Support Grips for Fiber Optics, Closed Mesh, Single Eye, Bale Length 8", Cable Diameter 17.53-22.35mm (.690-.880"), Approximate Break Strength 362.87kg (800 lbs)

**Documents:**

[Drawing \(PDF\)](#)  
[Brochure \(PDF\)](#)

[RoHS Certificate of Compliance \(PDF\)](#)

**Agency Certification**

CSA LR32159

**General**


Product Family	Cable Grips
Series	<a href="#">130094</a>
Eye Type	Single
O-Ring	N/A
Overview	<a href="#">Support Grips</a>
Product Name	Fiber Optic
Type	Support Grip
UPC	78678898773
<b>Physical</b>	
Approximate Break Strength	362.87kg (800 lbs)
Bale Length	0.203m (8.00")
Body Style	N/A
Cable Diameter	17.53-22.35mm (.690-.880")
Color - Grommet	N/A
Gender	N/A
Material - Body	Aluminum
Material - Grip	Non-magnetic Tin Bronze Wire
Mesh Length	0.152m (6.00")
Number of Holes	N/A
Thread Size	N/A

**Material Info**

Engineering Number 36676

**Reference - Drawing Numbers**

Sales Drawing SD-130094-001

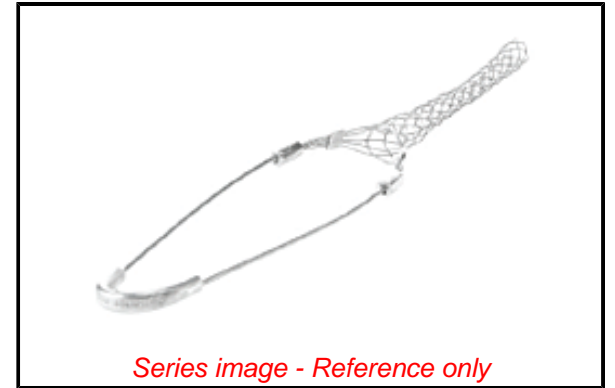

*Series image - Reference only*

**EU ELV**

**Not Reviewed**

**EU RoHS**

**Not Reviewed**

**REACH SVHC**

Not Reviewed

**Halogen-Free**

**Status**

**Not Reviewed**

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

**Search Parts in this Series**

[130094 Series](#)

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[1300940528](#)