

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1300940533](#)
Status: **Active**
Overview: [Support Grips](#)
Description: Support Grips for Fiber Optics, Closed Mesh, Single Eye, Bale Length 6", Cable Diameter 11.68-14.73mm (.460-.580"), Approximate Break Strength 2131.88kg (4700 lbs)

Documents:

[Drawing \(PDF\)](#)
[Brochure \(PDF\)](#)

[RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA LR32159

General


Product Family	Cable Grips
Series	130094
Eye Type	Single
O-Ring	N/A
Overview	Support Grips
Product Name	Fiber Optic
Type	Support Grip
UPC	78678836684
Physical	
Approximate Break Strength	181.44kg (400 lbs)
Bale Length	0.152m (6.00")
Body Style	Straight
Cable Diameter	11.68-14.73mm (.460-.580")
Color - Grommet	N/A
Gender	N/A
Material - Body	N/A
Material - Grip	Non-magnetic Tin Bronze Wire
Mesh Length	0.102m (4.00")
Number of Holes	N/A
Thread Size	N/A

Material Info

Engineering Number 36684

Reference - Drawing Numbers

Sales Drawing SD-130094-008

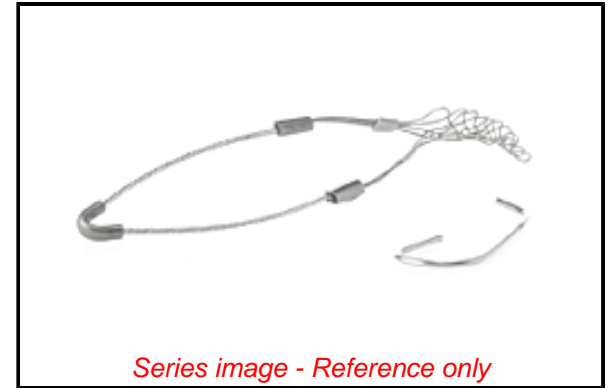

Series image - Reference only

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

Search Parts in this Series

[130094 Series](#)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[1300940533](#)