

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1300970259](#)
Status: **Active**
Overview: Strain-Relief Cord Grips
Description: Dust-Tight Strain Relief Wide Range Grip, 1/2" NPT, Straight Male, Cable Diameter 7.62-10.92mm (.300-.430"), Non-Insulated, Approximate Break Strength 136.08kg (300 lbs)

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA LR32159

General

Product Family	Cable Grips
Series	130097
Eye Type	N/A
Insulated	No
NEMA Rating	Dust Tight
O-Ring	N/A
Overview	Strain-Relief Cord Grips
Product Name	Dust-Tight
Type	Strain Relief Grip
UPC	78678834607
Use With	1/2" NPT MAX-LOC Lock Nut 1300990143 , MAX-LOC O-Ring, 1/2" NPT 1301800314 , 1/2" NPT MAX-LOC Gasket 1300990149

Physical


Approximate Break Strength	136.08kg (300 lbs)
Bale Length	N/A
Body Style	Straight
Cable Diameter	7.62-10.92mm (.300-.430")
Color - Grommet	N/A
Gender	Male
Material - Body	Zinc Plated Steel
Material - Grip	Galvanized Steel
Mesh Length	N/A
Number of Holes	N/A
Thread Size	1/2" NPT

Material Info

Engineering Number 36504

Reference - Drawing Numbers

Sales Drawing SD-130097-003

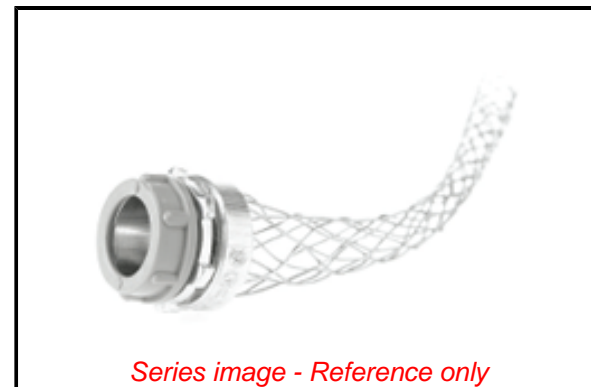

Series image - Reference only

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS Not Reviewed

ELV Not Reviewed

RoHS Phthalates Not Reviewed

Search Parts in this Series

[130097 Series](#)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[1300970259](#)