

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1300970268](#)
Status: **Active**
Overview: Strain-Relief Cord Grips
Description: Dust-Tight Strain Relief Wide Range Grip, 1-1/4" NPT, Straight Male, Cable Diameter 23.88-31.75mm (.940-1.250"), Non-Insulated, Approximate Break Strength 136.08kg (300 lbs)

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA LR32159

General

Product Family Cable Grips
 Series [130097](#)
 Eye Type N/A
 Insulated No
 NEMA Rating Dust Tight
 O-Ring N/A
 Overview [Strain-Relief Cord Grips](#)
 Product Name Dust-Tight
 Type Strain Relief Grip
 UPC 78678834612
 Use With 1 1/4" NPT Lock-Nut [1300990146](#)

Physical


Approximate Break Strength 136.08kg (300 lbs)
 Bale Length N/A
 Body Style Straight
 Cable Diameter 23.88-31.75mm (.940-1.250")
 Color - Grommet N/A
 Gender Male
 Material - Body Zinc Plated Steel
 Material - Grip Galvanized Steel
 Mesh Length N/A
 Net Weight 658.000/kg
 Number of Holes N/A
 Thread Size 1 1/4" NPT

Material Info

Engineering Number 36514

Reference - Drawing Numbers

Sales Drawing SD-130097-003

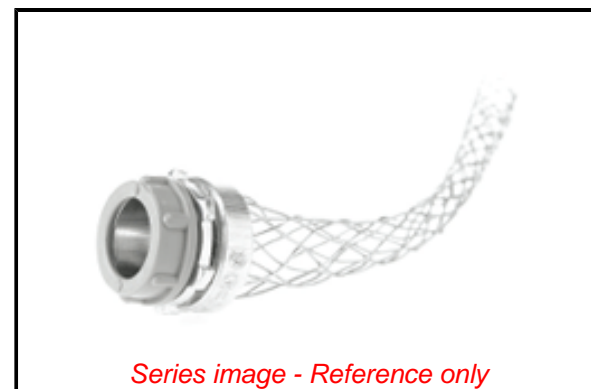

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Relevant

RoHS Phthalates

Not Reviewed

Search Parts in this Series

[130097 Series](#)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[1300970268](#)