

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [1300970334](#)  
**Status:** **Active**  
**Overview:** [Strain-Relief Cord Grips](#)  
**Description:** MAX-LOC Strain Relief Cord-Sealing Grip, 1" NPT, Straight Male, Cable Diameter 12.70-15.88mm (.500-.625"), Stainless Steel Mesh

**Documents:**

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)  
[Brochure \(PDF\)](#)

**Agency Certification**

CSA LR32159

**General**

Product Family Cable Grips  
 Series [130097](#)  
 Eye Type N/A  
 NEMA Rating NEMA 3R  
 O-Ring No  
 Overview [Strain-Relief Cord Grips](#)  
 Product Name MAX-LOC  
 Type Strain Relief Grip  
 UPC 78678837145  
 Use With MAX-LOC Lock Nut 1" NPT [1300990145](#) , MAX-LOC Gasket Sealing Ring 1" NPT [1300990151](#) , MAX-LOC O-Ring, 1" NPT [1301800334](#)

**Physical**


Approximate Break Strength N/A  
 Bale Length N/A  
 Body Style Straight  
 Cable Diameter 12.70-15.88mm (.500-.625")  
 Color - Grommet N/A  
 Gender Male  
 Material - Body Stainless Steel  
 Material - Grip Stainless Steel  
 Mesh Length N/A  
 Number of Holes 1  
 Thread Size 1" NPT

**Material Info**

Engineering Number 5548MSS

**Reference - Drawing Numbers**

Sales Drawing SD-130097-102

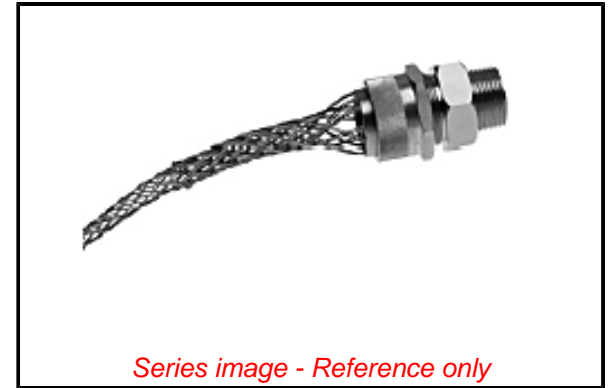

*Series image - Reference only*

**EU ELV**

**Not Reviewed**

**EU RoHS**

**Not Reviewed**

**REACH SVHC**

Not Reviewed

**Halogen-Free**

**Status**

**Not Reviewed**

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

**Search Parts in this Series**

[130097 Series](#)

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[1300970334](#)