

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1300980097](#)
Status: **Active**
Overview: Strain-Relief Cord Grips
Description: MAX-LOC Strain Relief Cord-Sealing Grip, 3/4" NPT, Straight Male, Cable Diameter 11.10-12.70mm (.437-.500"), Polyester

Documents:

[RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

UL E76954

General


| | |
|----------------|-----------------------------------------------------------------------------------------------------------------------------------------------------------------------------|
| Product Family | Cable Grips |
| Series | 130098 |
| Eye Type | N/A |
| NEMA Rating | NEMA 3R |
| O-Ring | No |
| Overview | <u>Strain-Relief Cord Grips</u> |
| Product Name | MAX-LOC |
| Type | Strain Relief Grip |
| UPC | 78678855361 |
| Use With | 3/4" NPT MAX-LOC Lock Nut 1300990144 , 3/4" NPT MAX-LOC Gasket Sealing Ring 1300990150 , 3/4" NPT MAX-LOC O-Ring 1301800333 |

Physical

| | |
|----------------------------|----------------------------|
| Approximate Break Strength | N/A |
| Bale Length | N/A |
| Body Style | Straight |
| Cable Diameter | 11.10-14.27mm (.437-.562") |
| Color - Grommet | Black |
| Gender | Male |
| Material - Body | Nylon |
| Material - Grip | N/A |
| Mesh Length | N/A |
| Number of Holes | 1 |
| Thread Size | 3/4" NPT |

Material Info

Engineering Number 5536BLK

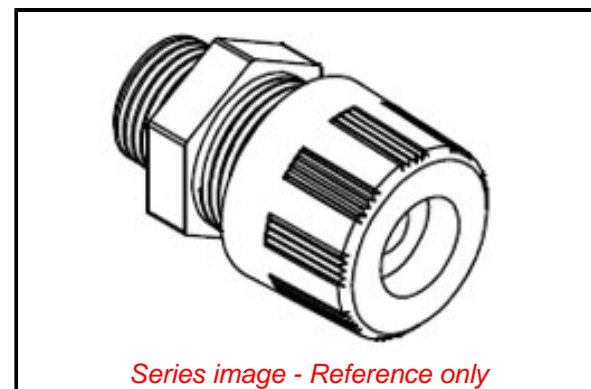

Series image - Reference only

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

Search Parts in this Series

[130098](#) Series

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[1300980097](#)