

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1300980106](#)
Status: **Active**
Overview: [Strain-Relief Cord Grips](#)
Description: MAX-LOC Strain Relief Cord-Sealing Grip, 3/4" NPT, Straight Male, Cable Diameter 12.70-15.88mm (.500-.625"), Stainless Steel Mesh and Nylon Compression Nut

Documents:
[Brochure \(PDF\)](#)

[RoHS Certificate of Compliance \(PDF\)](#)

General


Product Family	Cable Grips
Series	130098
Eye Type	N/A
NEMA Rating	NEMA 3R
O-Ring	No
Overview	Strain-Relief Cord Grips
Product Name	MAX-LOC
Type	Strain Relief Grip
UPC	78678829211
Use With	3/4" NPT MAX-LOC Lock Nut 1300990144 , 3/4" NPT MAX-LOC Gasket Sealing Ring 1300990150 , 3/4" NPT MAX-LOC O-Ring 1301800333

Physical

Approximate Break Strength	N/A
Bale Length	N/A
Body Style	Straight
Cable Diameter	12.70-15.88mm (.500-.625")
Color - Grommet	Gray
Gender	Male
Material - Body	Stainless Steel
Material - Grip	Stainless Steel
Mesh Length	N/A
Number of Holes	1
Thread Size	3/4" NPT

Material Info

Engineering Number	5538SS
--------------------	--------

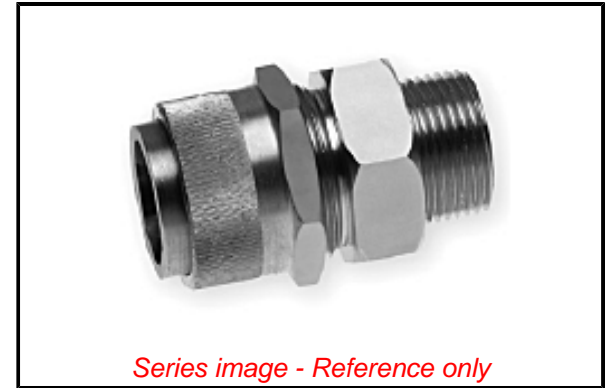

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

Search Parts in this Series

[130098](#) Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[1300980106](#)