

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [1300980202](#)  
**Status:** **Active**  
**Overview:** Strain-Relief Cord Grips  
**Description:** MAX-LOC Multi-Hole Strain Relief, 1/2" NPT, Straight Male, Cable Diameter 3.96mm (.156")

**Documents:**

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)  
[Brochure \(PDF\)](#)

**Agency Certification**

CSA LR32159  
 UL E76954

**General**

Product Family Cable Grips  
 Series [130098](#)  
 Comments Indicates that one or more grommet hole is covered by a thin membrane which can easily be "Poked" open if required.  
 Eye Type N/A  
 NEMA Rating NEMA 3R  
 O-Ring No  
 Overview [Strain-Relief Cord Grips](#)  
 Product Name MAX-LOC  
 Type Strain Relief Grip  
 UPC 78678850418  
 Use With 1/2" NPT MAX-LOC Lock Nut [1300990143](#) , MAX-LOC O-Ring, 1/2" NPT [1301800314](#) , 1/2" NPT MAX-LOC Gasket [1300990149](#)

**Physical**


Approximate Break Strength N/A  
 Bale Length N/A  
 Body Style Straight  
 Cable Diameter 3.96mm (.156")  
 Color - Grommet Yellow  
 Gender Male  
 Material - Body Nylon  
 Material - Grip N/A  
 Mesh Length N/A  
 Number of Holes 2, 3, or 4  
 Thread Size 1/2" NPT

**Material Info**

Engineering Number 5594-007

**Reference - Drawing Numbers**

Sales Drawing SD-130098-195

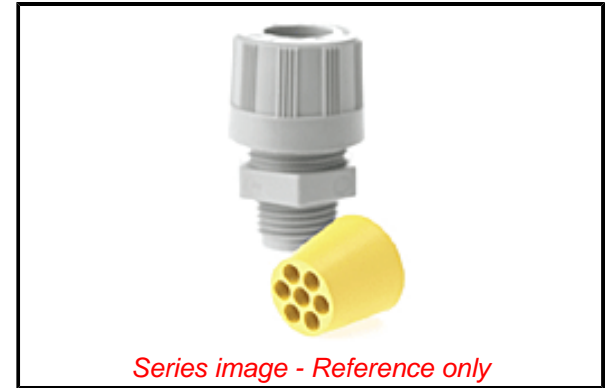

*Series image - Reference only*

**EU ELV**

**Not Reviewed**

**EU RoHS**

**Not Reviewed**

**REACH SVHC**

Not Reviewed

**Halogen-Free**

**Status**

**Not Reviewed**

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

**Search Parts in this Series**

[130098 Series](#)

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[1300980202](#)