

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1300980212](#)
Status: **Active**
Overview: Strain-Relief Cord Grips
Description: MAX-LOC Multi-Hole Strain Relief, 1/2" NPT, 90° Angle Male, Cable Diameter 4.75mm (.187")

Documents:
[Brochure \(PDF\)](#)

[RoHS Certificate of Compliance \(PDF\)](#)

General


Product Family	Cable Grips
Series	130098
Eye Type	N/A
NEMA Rating	NEMA 3R
O-Ring	Yes
Overview	<u>Strain-Relief Cord Grips</u>
Product Name	MAX-LOC
Type	Strain Relief Grip
UPC	78678838465
Use With	1/2" NPT MAX-LOC Lock Nut 1300990143 , MAX-LOC O-Ring, 1/2" NPT 1301800314 , 1/2" NPT MAX-LOC Gasket 1300990149

Physical

Approximate Break Strength	N/A
Bale Length	N/A
Body Style	90° Angle
Cable Diameter	4.75mm (.187")
Color - Grommet	N/A
Gender	Male
Material - Body	Nylon
Material - Grip	N/A
Mesh Length	N/A
Number of Holes	2, 3, 4, 5, 6, or 7
Thread Size	1/2" NPT

Material Info

Engineering Number	5595-008
--------------------	----------

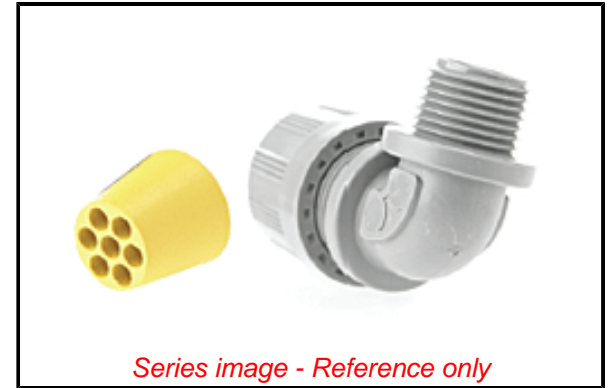

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

Search Parts in this Series

[130098 Series](#)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[1300980212](#)