

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1301110023](#)
Status: **Active**
Overview: [Stringlights](#)
Description: Pro-Yellow Stringlight, 150W, 14/2 AWM with 2.43m Lead, 10 Sockets with Guards, Overall Length 30.48m (100.0')

Documents:

[Brochure \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family	Portable Lighting
Series	130111
NEMA Configuration	N/A
NEMA Rating	Rain Tight
Outlet	None
Overview	Stringlights
Product Name	Pro-Yellow
Type	String Lights
UPC	78678853637

Physical


Cord Length - Primary	2.43m (8.0')
Cord Length - Secondary	0.61m (2.0')
Depth	N/A
Duty	General
Guard Included	Yes
Guard Type	Polypropylene
Height	N/A
Length	30.48m (100.0')
Material - Guard	Polypropylene
Mounting Style	Stringer
Net Weight	4.105/kg
Packaging Type	Carton
Socket Construction	Assembled

Electrical

Bulb Type	Incandescent
Cord Type - Primary	14/2
Lamp Type	A21
Lamp Wattage - Maximum	150W
Lumens	1500
On/Off Switch	No
Voltage (Fixture) - Maximum	120VAC 60 HZ

Material Info

Engineering Number	202SRL
--------------------	--------

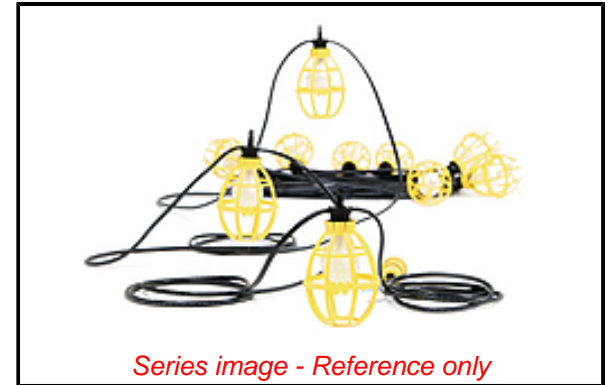

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

Search Parts in this Series

[130111 Series](#)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[1301110023](#)