

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1301230051](#)
Status: **Active**
Description: I-Beam Festoon Intermediate Car 605 S4

Documents:
[RoHS Certificate of Compliance \(PDF\)](#)

General


Product Family	Festoons
Series	130123
Cable Height - Maximum	19.05mm (.750")
Cable Width - Maximum	98.00mm (3.858")
Combined Cable Weight-Max./Car	79.38kg (175.0 lb)
Component Type	Car - Intermediate
Depth	156.46mm (6.160")
Duty	Heavy
Height	282.00 (11.100")
Length	254.00mm (10.000")
Product Name	Aero-Motive
Type	I-Beam
UPC	78678863063

Physical

Beam Size	S4 - 101.60mm
Material - Coating	Powder Coating
Material - Metal	Steel
Net Weight	764.340/g
Number of Cars	1
Packaging Type	Individual Carton
Saddle Radius	79.50mm (3.130")
Thread Size	N/A
Wire/Cable Type	Flat

Material Info

Engineering Number	0605411
--------------------	---------

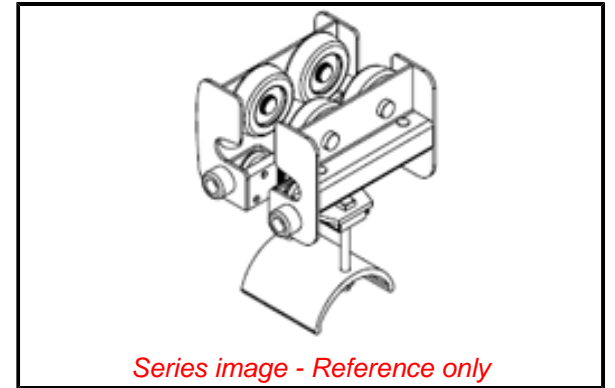

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

Search Parts in this Series

[130123 Series](#)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[1301230051](#)