

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [1301230088](#)  
**Status:** **Active**  
**Description:** I-Beam Festoon Intermediate Car 674 S4, for 4.0" I-Beam, Urethane Wheels and Kick-up Wheels

**Documents:**  
[RoHS Certificate of Compliance \(PDF\)](#)

**General**


Product Family	Festoons
Series	<a href="#">130123</a>
Cable Height - Maximum	11.43mm (.450")
Cable Width - Maximum	59.00mm (2.320")
Combined Cable Weight-Max./Car	79.38kg (175.0 lb)
Component Type	Car - Intermediate
Depth	156.46mm (6.160")
Duty	Heavy
Height	336.55mm (13.250")
Length	173.00mm (6.930")
Product Name	Aero-Motive
Type	I-Beam
UPC	78678863105

**Physical**

Beam Size	S4 - 101.60mm
Material - Coating	Powder Coating
Material - Metal	Steel
Material - Wheel	Polyurethane
Number of Cars	1
Packaging Type	Individual Carton
Saddle Radius	51.40mm (2.024")
Thread Size	N/A
Travel Speed - Maximum	121.92 mpm (400 fpm)
Wire/Cable Type	Flat

**Material Info**

Engineering Number	0674411
--------------------	---------

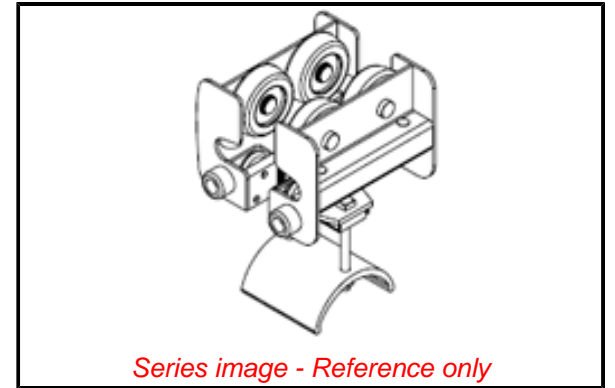

**EU ELV**

**Not Relevant**

**EU RoHS**

**Not Reviewed**

**REACH SVHC**

Not Reviewed

**Halogen-Free**

**Status**

**Not Reviewed**

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Relevant

RoHS Phthalates

Not Reviewed

**Search Parts in this Series**

[130123 Series](#)

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[1301230088](#)